

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0936010390

Status:


Active

Overview:

GWconnect Heavy Duty Connectors (HDC)

Description:

GWconnect Crimp Contact Insert, Female, 12-Pole, 16A, Numbered 1-24, Size 24B «104x27»

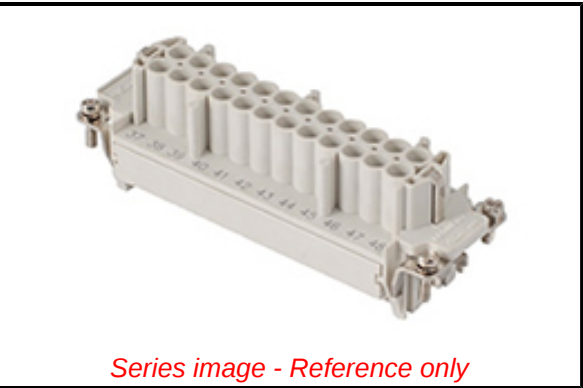

Documents:

RoHS Certificate of Compliance (PDF)

Agency Certification		
CSA		256883
UL		E249674
General		
Product Family		Industrial Connectors / Enclosures
Series		93601
Component Size		24B «104X27»
Component Type		Inserts - Crimp Contact
Insert Series		S-EHV
Overview		GWconnect Heavy Duty Connectors (HDC)
Product Category		Heavy Duty Connectors
Product Name		GWconnect
Standard		CSA C22.2 NO. 182.3, EN 60664-1, EN 61984, UL 1977
UPC		887191887487
Physical		
Durability (mating cycles max)		500
Flammability		UL 94V-0
Gender		Female
Insert Color		Grey
Material - Insert		Polycarbonate
Number of Rows		2
Packaging Type		Bag
Polarized to Mating Part		Yes
Poles		12
Stripping Length		7.50mm
Temperature Range - Operating		-40° to +125°C
Electrical		
Current - Maximum per Contact		16.0A
Voltage - Maximum		830V
Material Info		
Engineering Number		7510.6073.0

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - ED/88/2018 (15 January 2019)	
lead	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

93601 Series

Mates With

936010396 Male Screw Terminal Block Insert

Use With

Size 24B «104x27» Hoods and Housings

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[93601-0390](#)