

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1000570147

Status:


Active

Overview:

Temp-Flex Flat Ribbon Cable Solutions

Description:

Temp-Flex High-Performance Flat-Ribbon Cable, 12 Circuits, 1.27mm Pitch, 28 AWG, Silver Plated Copper, UL 20424, 7/36 Stranded Extruded FEP, Blue with Blue Polarity Stripe

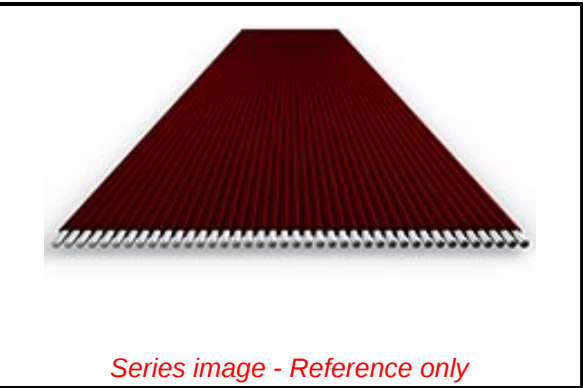

Documents:

[Drawing \(PDF\)](#)

[Brochure \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Cable
Series	100057
Crimp Quality Equipment	Yes
Overview	Temp-Flex Flat Ribbon Cable Solutions
Product Name	Temp-Flex
UPC	889056600538
Physical	
Cable Length	100 ft/spool, 10 ft min length
Circuits (Loaded)	12
Color - Cable Jacket	Blue w/Blue Polarity Stripe
Insulation	FEP
Material - Outer Jacket	FEP
Material - Plating Mating	Silver
Net Weight	7.425/g
Packaging Type	Spool
Pitch - Mating Interface	1.27mm
Temperature Range - Operating	-65° to +200°C
Wire Size AWG	28
Wire/Cable Type	7/36 Stranded, High-Performance Flat-Ribbon, UL 20424
Electrical	
Current - Maximum per Contact	1.5A
Voltage - Maximum	300V AC
Material Info	
Engineering Number	F2807S-12-050-55
Reference - Drawing Numbers	
Sales Drawing	1000572807BLUEBLUE-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

100057 Series

Use With

Molex Picoflex

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

100057-0147