


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200835015](#)
Status: **Active**
Overview: [Brad Ultra-Lock Connection System](#)
Description: Ultra-Lock (M12) Single-Ended Cordset, 12 Poles, Male (Straight) to Pigtail, 26 AWG, PUR Cable, 2.0m (6.56') Length, Black

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Industrial Cordsets
Series	120083
Connector End A	Ultra-Lock (M12)
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Ultra-Lock Connection System
Product Name	Ultra-Lock (M12)
Region	America
Type	Single Ended
UPC	883906540784
Physical	
Cable Diameter	6.50mm (.256")
Cable Length	2.0m (6.56')
Color - Cable Jacket	Yellow
Coupling Style	Push to Lock
Gender	Male-Pigtail
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PUR
Material - Connector Body	PUR
Material - Coupling Nut	Nickel-plated Brass
Material - O-Ring	Fluoro-elastomer
Material - Plating Mating	Gold
Orientation	Straight to Pigtail
Poles	12
Temperature Range - Operating	-25° to +90°C
Wire Size AWG	26
Wire/Cable Type	UL 20549
Electrical	
Current - Maximum per Contact	1.5A
Voltage - Maximum	30V AC/DC
Material Info	
Engineering Number	W0CS06P45M020
Reference - Drawing Numbers	
Sales Drawing	SD-W0CS06P45MXXX-001

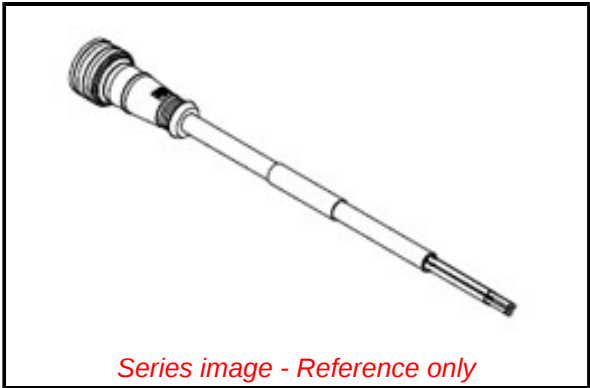

Series image - Reference only

EU ELV Not Reviewed	
EU RoHS Not Reviewed REACH SVHC Not Reviewed Halogen-Free Status Not Reviewed	China RoHS
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[120083](#) Series

Mates With
[120341](#) Micro-Change CAT6A Receptacles

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1200835015