

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1200845159

Status:

Active

Overview:

Brad Ultra-Lock Connection System

Description:

Ultra-Lock (M12) Receptacle, 5 Poles, PG9 Mounting Threads, Female (Straight) to 0.34mm² PVC Leads, 0.30m (11.81") Length

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

LR6837

General

Product Family

Series

IP Rating

NEMA Rating

Overview

Product Name

Type

UPC

Industrial Receptacles

120084

IP69K

NEMA 6

Brad Ultra-Lock Connection System

Ultra-Lock (M12)

Single Ended (pigtail)

884982225268

Physical

Coupling Type

Gender

Keyway

Length

Material - Component

Mounting Thread Size

Net Weight

Orientation

Panel Mount

Poles

Temperature Range - Operating

Wire Size AWG

Wire/Cable Type

Internal Thread

Female

Single

0.30m

Nickel-plated Brass

PG9

3.000/g

Straight

Front

5

-25° to +90°C

22

UL 1569

Electrical

Current - Maximum per Contact

Voltage - Maximum

4.0A

60V

Material Info


Engineering Number

WR5J20E03C3003

Reference - Drawing Numbers

Sales Drawing

SD-120084-030-001

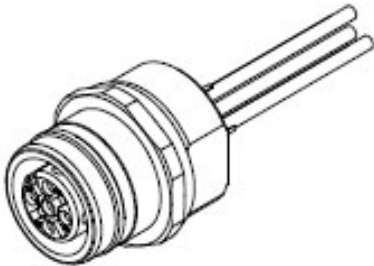

Series image - Reference only

EU ELV Not Reviewed	
EU RoHS Compliant with Exemption 6(c) REACH SVHC Contained Per - D(2021)4569-DC (8 July 2021) Lead Halogen-Free Status Not Relevant	China RoHS
For more information, please visit Contact US	
China ROHS ELV RoHS Phthalates	Not Relevant Not Reviewed Not Contained

Search Parts in this Series

120084 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[1200845159](#)