

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1210360791](#)
Status: **Active**
Overview: mPm DIN Valve Connectors
Description: Micro-Change (M12) to Brad mPm DIN Form B - 11mm Cordset, S0 Circuit, Yellow LED, 5 Poles, Male (Straight) to Male (90°), 2.0m (6.56') Length, 110V

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Industrial Cordsets
Series [121036](#)
Connector End A Brad mPm DIN B - 11mm
Connector End B Micro-Change (M12)
IP Rating IP65
Material - Contact Copper Alloy
Overview [mPm DIN Valve Connectors](#)
Product Name Micro-Change (M12), mPm
Protocol N/A
Region America, Europe
Type Double Ended
UPC 78172534563

Physical
Cable Diameter 5.72mm (.225")
Cable Length 2.0m (6.56')
Color - Cable Jacket Black
Coupling Style Threaded
Gender Male-Male
Keyway Single
LED Indicator Yellow
Material - Cable Jacket PUR
Material - Connector Body Polypropylene
Material - Coupling Nut Nickel-plated Brass
Material - Plating Mating Gold
Net Weight 123.679/g
Orientation 90° to Straight
Poles 5
Temperature Range - Operating -25° to +75°C
Wire Size AWG 22
Wire/Cable Type Shielded PUR

Electrical
Current - Maximum per Contact 1.5A
Voltage - Maximum 110V

Material Info
Engineering Number F850D0P12M020

Reference - Drawing Numbers
Sales Drawing SD-121036-002-001

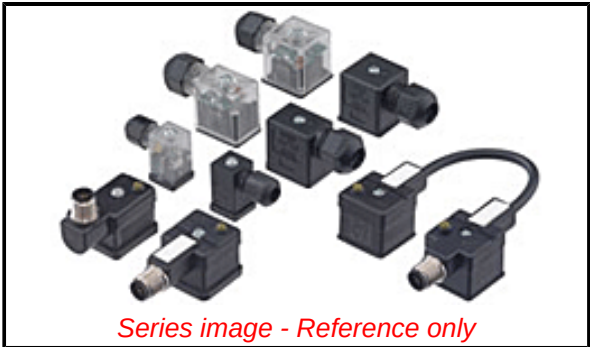

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[121036](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

[1210360791](#)