

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300060874](#)
Status: **Active**
Overview: [Brad Mini-Change Connectors](#)
Description: Mini-Change A-Size Single-Ended Cordset, 4 Poles, Female (Straight) to Pigtail, 16 AWG, Rubber Cable, 6.10m (20.0') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family Industrial Cordsets
Series [130006](#)
Connector End A Mini-Change
Connector End B Pigtail
IP Rating IP67
Material - Contact Copper Alloy
Overview [Brad Mini-Change Connectors](#)
Product Name Mini-Change
Protocol N/A
Region America
Type Single Ended
UPC 78678843117

Physical


Cable Diameter 11.43mm (.450")
Cable Length 6.10m (20.0')
Color - Cable Jacket Yellow
Coupling Style Threaded
Gender Female-Pigtail
Keyway Single
LED Indicator No
Material - Cable Jacket Rubber
Material - Connector Body PVC
Material - Coupling Nut Black Epoxy Coated Zinc
Material - Plating Mating Gold
Orientation Straight to Pigtail
Poles 4
Temperature Range - Operating -20° to +90°C
Wire Size AWG 16
Wire/Cable Type SOO

Electrical

Current - Maximum per Contact 10.0A
Voltage - Maximum 600V

Material Info

Engineering Number 104000C01F200

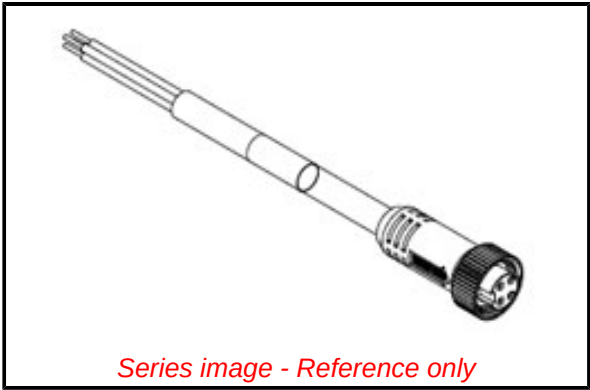

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[130006](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300060874