

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300500105

Status:


Active

Overview:

Brad Industrial Ethernet Solutions

Description:

Brad RJ-Lnxx RJ-45 Single-Ended Cordset, 8 Poles, Male to Pigtail, Straight, Shielded Cable, 1.0m (3.28') Length , 26 AWG

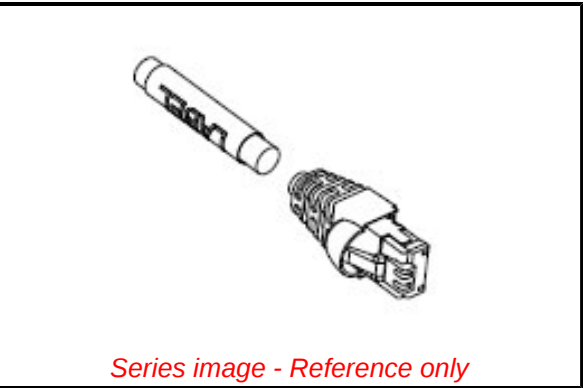

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Industrial Cordsets
Series	130050
Connector End A	RJ-45 (standard)
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Industrial Ethernet Solutions
Performance Category	5e
Product Name	Brad, RJ-Lnxx
Protocol	N/A
Region	America, Asia, Europe
Type	Single Ended
UPC	78678850644
Physical	
Cable Diameter	7.37mm (.290")
Cable Length	1.0m (3.28')
Color - Cable Jacket	Black
Coupling Style	N/A
Gender	Male-Pigtail
Keyway	None
LED Indicator	No
Material - Cable Jacket	PUR
Material - Connector Body	PVC
Material - Coupling Nut	N/A
Material - Plating Mating	N/A
Orientation	Straight to Pigtail
Poles	8
Temperature Range - Operating	-20° to +80°C
Wire Size AWG	26
Wire/Cable Type	Shielded-Twisted Pair
Electrical	
Current - Maximum per Contact	1.5A
Voltage - Maximum	30V
Material Info	
Engineering Number	ENP1305M010
Reference - Drawing Numbers	
Sales Drawing	SD-130050-013-001

EU ELV	
Not Reviewed	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

130050 Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300500105