

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300500277

Status:


Active

Overview:

Brad Industrial Ethernet Solutions

Description:

Brad RJ-Lnxx RJ-45 Single-Ended Cordset, 8 Poles, Male (Straight) to Pigtail, 24 AWG, PUR Cable, 1.0m (3.28') Length

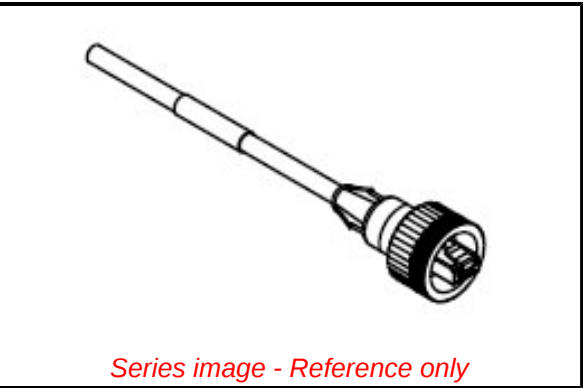

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Industrial Cordsets
Series	130050
Connector End A	RJ-45 (industrial)
Connector End B	Pigtail
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Industrial Ethernet Solutions
Performance Category	5e
Product Name	Brad, RJ-Lnxx
Protocol	N/A
Region	America, Asia, Europe
Type	Single Ended
UPC	78678843497

Physical	
Cable Diameter	6.35mm (.250")
Cable Length	1.0m (3.28')
Color - Cable Jacket	Black
Coupling Style	Threaded
Gender	Male-Pigtail
Keyway	None
LED Indicator	No
Material - Cable Jacket	PUR
Material - Connector Body	PUR
Material - Coupling Nut	ABS
Material - Plating Mating	N/A
Orientation	Straight to Pigtail
Poles	8
Temperature Range - Operating	-20° to +80°C
Wire Size AWG	24
Wire/Cable Type	Shielded-Twisted Pair

Electrical	
Current - Maximum per Contact	1.5A
Voltage - Maximum	30V

Material Info	
Engineering Number	ENS1105M010

Reference - Drawing Numbers	
Sales Drawing	SD-130050-025-001

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

130050 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1300500277