

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1731100075

Status:


Active

Overview:

FCT D-Sub Connectors

Description:

FCT Standard-Density Waterproof D-Sub Connector, Male, Right-Angle, PCB Through Hole, Gold over Nickel Phosphorus Plating, Metal Watertight Frame, Snap-in Bolt, 25 Circuits

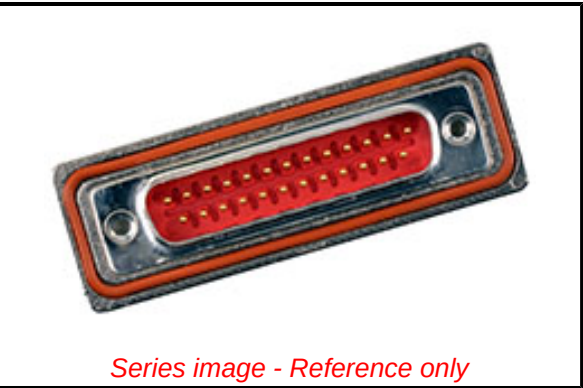

Documents:

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

Brochure (PDF)

General	
Product Family	D-Sub Products
Series	173110
IP Rating	IP67
Overview	FCT D-Sub Connectors
Product Category	D-Sub Connector
Product Name	FCT Products
Type	Standard Density
UPC	889056487443
Physical	
Circuits (Loaded)	25
Circuits (maximum)	25
Color - Resin	Red
Durability (mating cycles max)	500
Gender	Male
Material - Contact	Copper Alloy
Material - Resin	PBT
Material - Shell	Brass
Net Weight	37.400/g
Number of Rows	2
Orientation	Right-Angle
PC Tail Length	10.50mm
PCB Locator	Yes
PCB Retention	Yes
PCB Thickness - Recommended	1.60mm
Packaging Type	Carton
Panel Mount	Rear
Panel Mount Method	Thread-In
Pitch - Mating Interface	2.84mm
Pitch - Termination Interface	2.54mm
Plating - Contact	Gold over Nickel Phosphorus
Plating - Shell	Tin
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Ports	1
Shielded	Yes
Temperature Range - Operating	-25° to +70°C
Termination Style	Through Hole
Waterproof / Dustproof	Yes
Waterproof / Dustproof Type	IP67
Electrical	
Current - Maximum per Contact	7.5A
Material Info	

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2020)4578-DC (25 June 2020)

lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

173110 Series

Mates With

FCT Standard Density D-Sub, Size 3, 25 Position, Socket

Use With

FCT D-Sub Dust Caps

This document was generated on 07/27/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[173110-0075](#)