

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1731130068

Status:


Active

Overview:

FCT D-Sub Connectors

Description:

FCT High-Density D-Sub Connector, Female, Straight, PCB Through Hole, Gold Plating, 6.60mm Snap-in Bolt, 15 Circuits

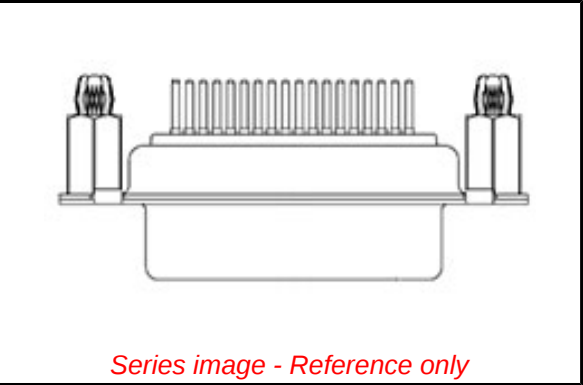

Series image - Reference only

Documents:

Brochure (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	D-Sub Products
Series	173113
IP Rating	IP20
Overview	FCT D-Sub Connectors
Product Category	D-Sub Connector
Product Name	FCT Products
Type	High Density
UPC	889056411714
Physical	
Circuits (Loaded)	15
Circuits (maximum)	15
Color - Resin	Black
Durability (mating cycles max)	50
Gender	Female
Material - Contact	Copper Alloy
Material - Resin	PBT
Material - Shell	Steel
Net Weight	6.800/g
Number of Rows	3
Orientation	Straight
PC Tail Length	9.50mm
PCB Locator	Yes
PCB Retention	Yes
PCB Thickness - Recommended	1.60mm
Packaging Type	Carton
Panel Mount	Rear
Panel Mount Method	Thread-In
Pitch - Mating Interface	1.98mm
Pitch - Termination Interface	1.98mm
Plating - Contact	Gold over Nickel
Plating - Shell	Tin
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Ports	1
Shielded	Yes
Temperature Range - Operating	-55° to +105°C
Termination Style	Through Hole
Waterproof / Dustproof	No
Waterproof / Dustproof Type	IP20
Electrical	
Current - Maximum per Contact	3.0A
Material Info	
Engineering Number	CT09-15S1-0982

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

173113 Series

Mates With

FCT High-Density D-Sub, Size 1, 15 Position, Plug

This document was generated on 07/27/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

173113-0068