

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1731130094](#)
Status: **Active**
Overview: [FCT D-Sub Connectors](#)
Description: FCT High-Density D-Sub Connector, Female, Straight, PCB Through Hole, Gold Plating, 6.60mm Snap-in Bolt, 62 Circuits


Documents:
[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General
Product Family D-Sub Products
Series [173113](#)
IP Rating IP20
Overview [FCT D-Sub Connectors](#)
Product Category D-Sub Connector
Product Name FCT Products
Type High Density
UPC 889056490078

Physical
Circuits (Loaded) 62
Circuits (maximum) 62
Color - Resin Black
Durability (mating cycles max) 50
Gender Female
Material - Contact Copper Alloy
Material - Resin PBT
Material - Shell Steel
Net Weight 17.000/g
Number of Rows 3
Orientation Straight
PC Tail Length 9.50mm
PCB Locator Yes
PCB Retention Yes
PCB Thickness - Recommended 1.60mm
Packaging Type Carton
Panel Mount Rear
Panel Mount Method Thread-In
Pitch - Mating Interface 1.98mm
Pitch - Termination Interface 1.98mm
Plating - Contact Gold over Nickel
Plating - Shell Tin
Polarized to Mating Part Yes
Polarized to PCB Yes
Ports 1
Shielded Yes
Temperature Range - Operating -55° to +105°C
Termination Style Through Hole
Waterproof / Dustproof No
Waterproof / Dustproof Type IP20

Electrical
Current - Maximum per Contact 3.0A

Material Info
Engineering Number CT37-62S1-0982

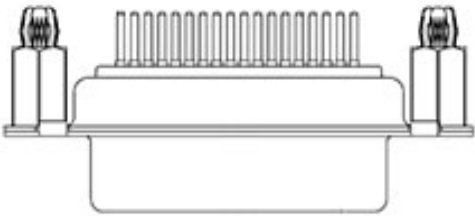

Series image - Reference only

EU ELV
Not Reviewed

EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[173113 Series](#)

Mates With
FCT High-Density D-Sub, Size 4, 62 Position, Plug

This document was generated on 07/26/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

173113-0094