

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1731140277

Status:


Active

Overview:

FCT D-Sub Connectors

Description:

FCT Standard-Density Dual-Port D-Sub Connector, Female, Right-Angle, PCB Through Hole, Gold Plating, 200 Mating Cycles, Medium Mounting Height, Snap-in Bolt, 15 Circuits per Port

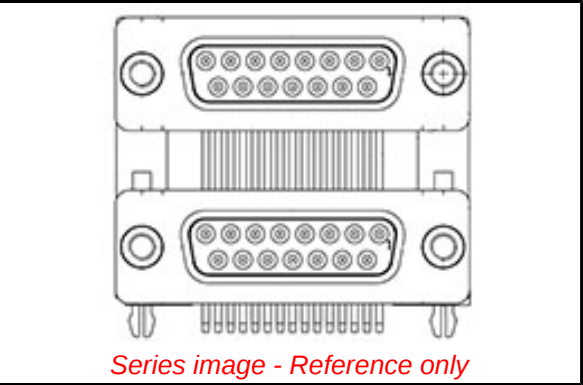

Documents:

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

Brochure (PDF)

General	
Product Family	D-Sub Products
Series	173114
IP Rating	IP20
Overview	FCT D-Sub Connectors
Product Category	D-Sub Connector
Product Name	FCT Products
Type	Standard Density
UPC	191128829786
Physical	
Circuits (Loaded)	30
Circuits (maximum)	30
Color - Resin	Black
Durability (mating cycles max)	200
Gender	Female
Material - Contact	Copper Alloy
Material - Resin	PBT
Material - Shell	Steel
Net Weight	30.000/g
Number of Rows	4
Orientation	Right-Angle
PC Tail Length	9.40mm
PCB Locator	Yes
PCB Retention	Yes
PCB Thickness - Recommended	1.60mm
Packaging Type	Carton
Panel Mount	Rear
Panel Mount Method	Thread-In
Pitch - Mating Interface	2.84mm
Pitch - Termination Interface	2.54mm
Plating - Contact	Gold over Nickel
Plating - Shell	Tin
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Ports	2
Shielded	Yes
Temperature Range - Operating	-55° to +130°C
Termination Style	Through Hole
Waterproof / Dustproof	No
Waterproof / Dustproof Type	IP20
Electrical	
Current - Maximum per Contact	5.0A
Material Info	

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

173114 Series

Mates With

FCT Standard-Density D-Sub, Size 2, 15 Position, Plug

This document was generated on 07/28/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

173114-0277