

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2004850410

Status:


Active

Overview:

Easy-On FFC FPC Connectors

Description:

Easy-On FFC/FPC One-Touch Connector, 0.50mm Pitch, Right-Angle, Bottom Contact, 4.46mm Height, 105°C Operating Temperature, 10 Circuits, Gold (Au) Plating

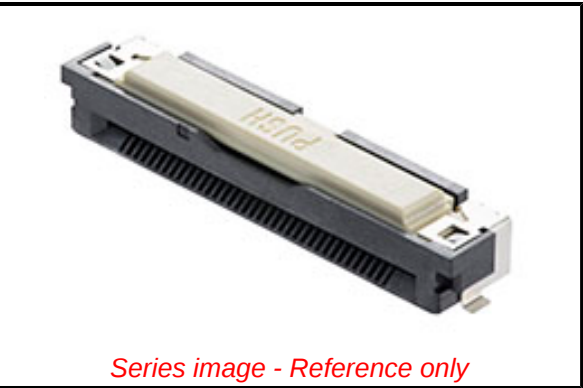

Documents:

3D Model

Drawing (PDF)

3D Model (PDF)

Product Specification 2004851400-PS-000 (PDF)

Packaging Specification 2004859200-SPK-200 (PDF)

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	FFC/FPC Connectors
Series	200485
Overview	Easy-On FFC FPC Connectors
Product Name	Easy-On
UPC	191130074365
Physical	
Actuator Type	One-Touch
Circuits (Loaded)	10
Circuits (maximum)	10
Color - Resin	Black
Contact Position	Bottom
Durability (mating cycles max)	20
Mated Height	4.46mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Resin	Liquid Crystal Polymer
Net Weight	358.548/mg
Number of Rows	1
Orientation	Right Angle
PCB Mounting	Surface Mount
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.50mm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire/Cable Type	FFC/FPC
Electrical	
Current - Maximum per Contact	0.5A
Voltage - Maximum	50V
Material Info	
Reference - Drawing Numbers	
Packaging Specification	2004859200-SPK-200
Product Specification	2004851400-PS-000
Sales Drawing	2004850400-000, 2004851400-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

200485 Series

Mates With

Premo-Flex FFC Cable [15016](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

200485-0410