

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2039560301

Status:


Active

Overview:

SlimStack Board-to-Board Connectors

Description:

SlimStack Board-to-Board Connector, 0.40mm Pitch, FSB5 Floating Series, Plug, 5.00mm Mated Height, 3.80 Mated Width, 30 Circuits

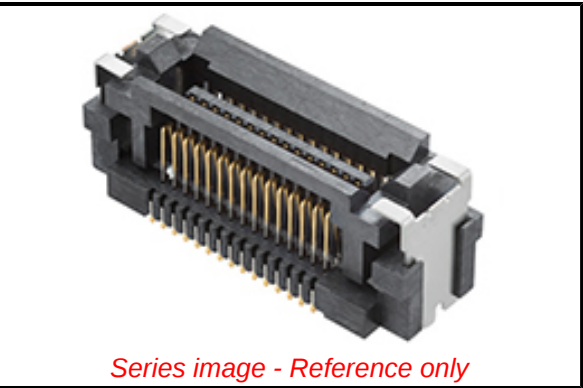

Series image - Reference only

Documents:

3D Model	Product Literature (PDF)
Drawing (PDF)	Product Literature (PDF)
Product Specification 2039550000-000 (PDF)	Product Literature (PDF)
Application Specification 2039550000-001 (PDF)	Product Literature (PDF)
Packaging Specification 2039569200-SPK-200 (PDF)	Product Literature (PDF)
RoHS Certificate of Compliance (PDF)	Product Literature (PDF)

General

Product Family	PCB Headers
Series	203956
Application	Board-to-Board, Signal
CURRENT-MAX-NUMERIC	0.3
Overview	SlimStack Board-to-Board Connectors
PITCH-MATING-NUMERIC	0.40
Product Literature Order No	987651-8822_ZH, 987651-8824_DE, 987651-8825_JA, 987651-8826_KO, 987651-8827_ES, 987651-9871
Product Name	SlimStack
Series Name	FSB5
UPC	191128870153

Physical

Breakaway	No
Circuits (Loaded)	30
Circuits (maximum)	30
Color - Resin	Black
Durability (mating cycles max)	30
Glow-Wire Capable	No
Guide to Mating Part	No
Keying to Mating Part	None
Lock to Mating Part	None
Mated Height	5.00mm
Mated Width	3.80mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Material - Resin	Liquid Crystal Polymer
Net Weight	145.963/mg
Number of Rows	2
Orientation	Vertical
PCB Locator	No
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.40mm
Pitch - Termination Interface	0.40mm
Polarized to Mating Part	No
Polarized to PCB	No
Temperature Range - Operating	-40° to +125°C
Termination Interface: Style	Surface Mount

Electrical

Current - Maximum per Contact	0.3A
-------------------------------	------

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/71/2019 (16 July 2019)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

203956 Series

Mates With

SlimStack Receptacle 203955

Voltage - Maximum	40V AC (RMS)/DC
Material Info	
Reference - Drawing Numbers	
Application Specification	2039550000-001
Packaging Specification	2039569200-SPK-200
Product Specification	2039550000-000
Sales Drawing	2039560000-001, 2039561000-000

This document was generated on 08/29/2019
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[203956-0301](#)