


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2047230012](#)
Status: **Active**
Overview: [Mini-Fit Family Power Connectors](#)
Description: [Mini-Fit Jr. Hermaphroditic Backshell, 12 Circuits, Low-Halogen, Black](#)

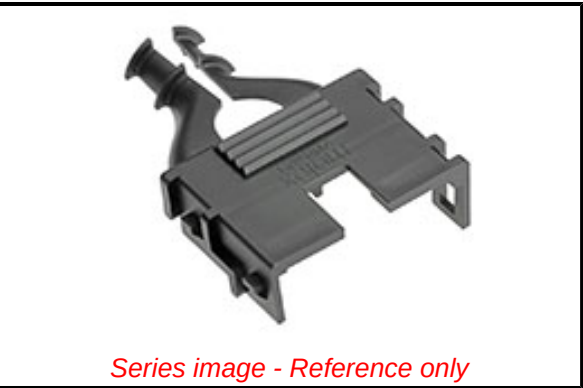

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[3D Model \(PDF\)](#)
[Product Specification 2047230001-PS-000 \(PDF\)](#)
[Application Specification 2047230000-AS-000 \(PDF\)](#)
[Packaging Specification 2047230001-PK-000 \(PDF\)](#)
[Test Summary 2047230000-TS-000 \(PDF\)](#)
[Datasheet \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General
Product Family [Accessories](#)
Series [204723](#)
Component Type [Backshell](#)
Overview [Mini-Fit Family Power Connectors](#)
Product Name [Mini-Fit Jr.](#)
UPC [191128862882](#)

Physical
Circuits (Loaded) [12](#)
Circuits (maximum) [12](#)
Color - Resin [Black](#)
Gender [Hermaphroditic](#)
Material - Resin [Nylon](#)
Net Weight [2.933/g](#)
Number of Rows [2](#)
Packaging Type [Bag](#)
Temperature Range - Operating [-40° to +105°C](#)

Material Info

Reference - Drawing Numbers
[Application Specification](#) [2047230000-AS-000](#)
[Packaging Specification](#) [2047230001-PK-000](#)
[Product Specification](#) [2047230001-PS-000](#)
[Sales Drawing](#) [2047230000-SD-000](#)
[Test Summary](#) [2047230000-TS-000](#)

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
D(2021)4569-DC (8
July 2021)
Halogen-Free
Status
Low-Halogen
For more information, please visit [Contact US](#)

China ROHS [Green Image](#)
ELV [Not Relevant](#)
RoHS Phthalates [Not Contained](#)

Search Parts in this Series
[204723 Series](#)

Use With
[Mini-Fit Jr. Plug Housing](#)
(without Panel Mount) [5559](#)
query:productseries:5559@panelmount:No

 [Mini-Fit Jr. Receptacle Housing 5557](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[204723-0012](#)