

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2149212115

Status:


Active

Overview:

Off-the-Shelf Pre-Crimped Leads

Description:

Pre-Crimped Lead PicoBlade Female-to-Pigtail, Gold (Au) Plating, 450.00mm Length, 28 AWG, Black

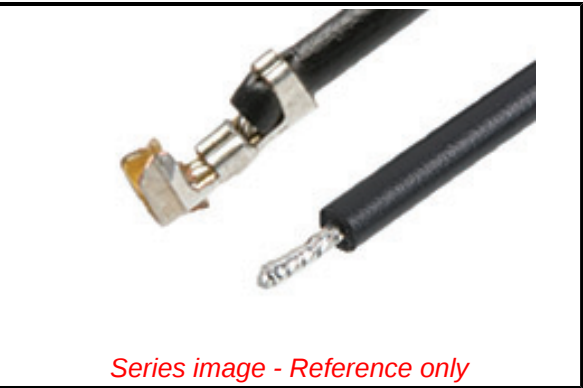

Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

[Datasheet \(PDF\)](#)

General	
Product Family	Cable Assemblies
Series	214921
Assembly Configuration	Pre-crimped Lead Only
Connector to Connector	PicoBlade Terminal-to-Pigtail
Overview	Off-the-Shelf Pre-Crimped Leads
Product Name	PicoBlade
UPC	193264502813
Physical	
Cable Length	450.00mm
Circuits (Loaded)	1
Color - Resin	Black
Gender	Female-Pigtail
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Net Weight	0.750/g
Packaging Type	Bag
Plating min - Mating	0.380µm
Single Ended	Yes
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.04mm max.
Wire Size AWG	26
Wire/Cable Type	UL 1061
Electrical	
Current - Maximum per Contact	1.0A
Voltage - Maximum	125V AC (RMS)/DC
Material Info	
Reference - Drawing Numbers	
Sales Drawing	2149212121-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

214921 Series

Use With

51021 PicoBlade Crimp Housing

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[214921-2115](#)