

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2152723803](#)
Status: **Active**
Overview: Temperature Sensor Cable Assemblies
Description: Epoxy Coated NTC Thermistor Cables, 25.00mm Length, 3982 Beta Value, 30k# Resistance at 25°C with 1% Tolerance, Yellow

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Datasheet \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	215272
Application	Temperature Sensing
Assembly Configuration	Single Ended Connector
Beta Value (K)	3982
Connector to Connector	NTC Thermistor-to-Pigtail
Overview	Temperature Sensor Cable Assemblies
Product Name	NTC Temperature Sensor
Resistance Tolerance (%)	1
Resistance at 25°C (kohms)	30
UPC	193264876433


Physical

Cable Length	25.00mm
Circuits (Loaded)	1
Color - Resin	Yellow
Gender	N/A
Lock to Mating Part	Yes
Net Weight	0.110/g
Packaging Type	Bag
Single Ended	Yes
Wire Size AWG	28
Wire/Cable Type	N/A

Material Info

Reference - Drawing Numbers

Sales Drawing	2152723803-000
---------------	----------------

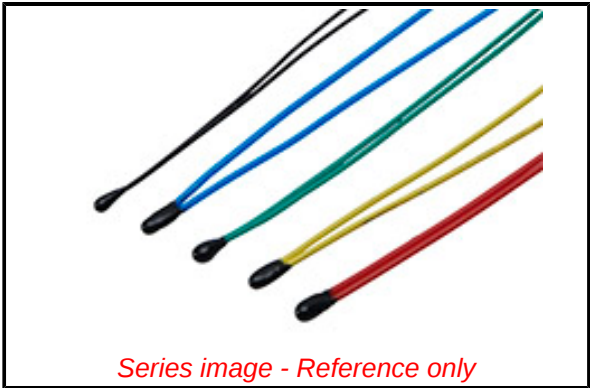

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 15(a)

REACH SVHC

Contained Per -
D(2020)9139-DC (19
Jan 2021)
Lead

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[215272](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

215272-3803