

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2177932125](#)
Status: **Active**
Overview: Off-the-Shelf Pre-Crimped Leads
Description: Pre-Crimped Lead Squba 1.8 Male-to-Pigtail, Tin (Sn) Plating, 450.00mm Length, 22 AWG, Red

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Datasheet \(PDF\)](#)

General

Product Family Cable Assemblies
Series [217793](#)
Assembly Configuration Pre-crimped Lead Only
Connector to Connector Squba Crimp Terminals
Overview Off-the-Shelf Pre-Crimped Leads
Product Name Squba
UPC 195842124660

Physical

Cable Length 450.00mm
Circuits (Loaded) 1
Color - Resin Red
Gender Male-Pigtail
Lock to Mating Part Yes
Material - Metal Copper Alloy
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin PVC
Net Weight 2.131/g
Number of Rows 1
Packaging Type Bag
Single Ended Yes
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 0.95mm-1.40mm
Wire Size AWG 22
Wire/Cable Type UL 10002


Electrical

Current - Maximum per Contact 6.0A
Voltage - Maximum 125V

Material Info

Reference - Drawing Numbers

Sales Drawing 2177931121-000

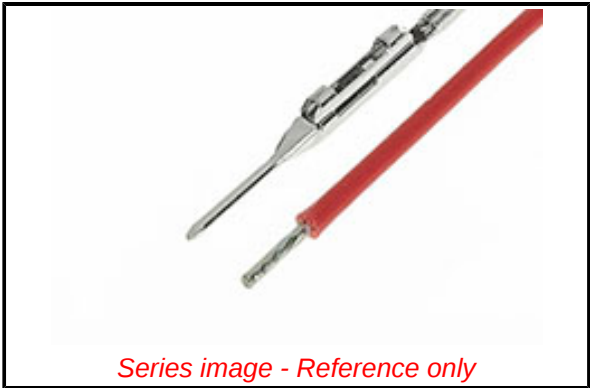

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[217793](#) Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[217793-2125](#)