

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

5041930700

Status:


Active

Overview:

Micro-Lock™ Connectors

Description:

Micro-Lock 1.25mm Pitch Single-Row Crimp Housing, White, 7 Circuits, 5041930700

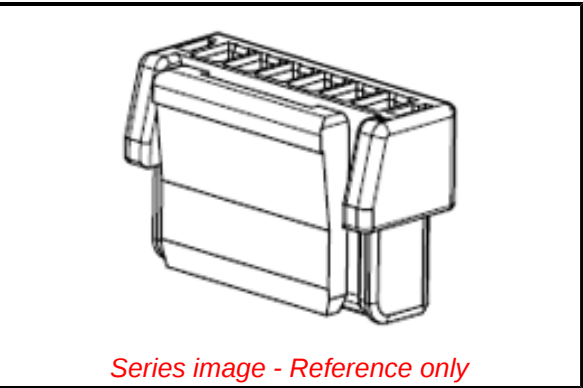

Documents:

3D Model

Drawing (PDF)

Product Specification PS-504193-001-001 (PDF)

Application Specification AS-504193-001-001 (PDF)

Application Specification AS-504193-002-001 (PDF)

Packaging Specification SPK-504193-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Housings
Series	504193
Application	Wire-to-Board
Overview	Micro-Lock™ Connectors
Product Name	Micro-Lock
UPC	887191165615
Physical	
Circuits (maximum)	7
Color - Resin	White
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	Polyester
Net Weight	135.840/mg
Number of Rows	1
Packaging Type	Tray
Panel Mount	No
Pitch - Mating Interface	1.25mm
Pitch - Termination Interface	1.25mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-25° to +85°C
Electrical	
Current - Maximum per Contact	1.5A
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-504193-001-001, AS-504193-002-001
Packaging Specification	SPK-504193-001-001
Product Specification	PS-504193-001-001
Sales Drawing	SD-504193-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ED/71/2019 (16 July 2019)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

504193 Series

Mates With

504194 Micro-Lock 1.25mm Pitch Vertical Header, 504195 Micro-Lock 1.25mm Pitch Right Angle Header

Use With

Micro-Lock Wire-to-Board Crimp Terminal 5041851000

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

504193-0700