

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

5054050760

Status:


Active

Overview:

CLIK-Mate Wire-to-Board Connectors

Description:

1.50mm Pitch, CLIK-Mate PCB Receptacle, Single Row, Surface Mount, Vertical, Gold Plating, Positive Lock, with Pick-and-Place Polyimide Tape, 7 Circuits, Natural

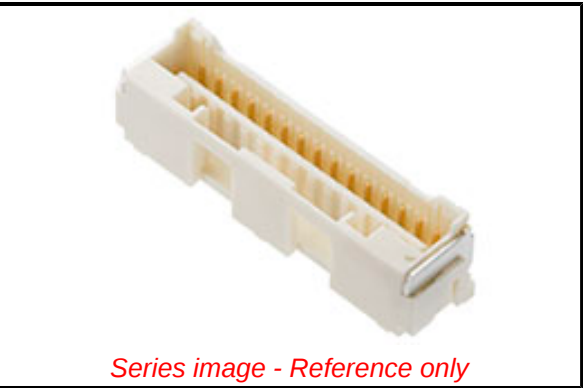

Series image - Reference only

Documents:	
3D Model	Application Specification AS-502578-001-001 (PDF)
Drawing (PDF)	Application Specification AS-502578-002-001 (PDF)
3D Model (PDF)	Packaging Specification SPK-505405-001-001 (PDF)
Product Specification PS-505405-001-001 (PDF)	RoHS Certificate of Compliance (PDF)

General	
Product Family	PCB Receptacles
Series	505405
Application	Signal, Wire-to-Board
Comments	See Product Specification for maximum current rating by wire AWG, See Product Specification for maximum current rating by wire AWG
Overview	CLIK-Mate Wire-to-Board Connectors
Product Name	CLIK-Mate
UPC	889056171700
Physical	
Circuits (Loaded)	7
Circuits (maximum)	7
Color - Resin	Beige
Durability (mating cycles max)	30
Glow-Wire Capable	No
Guide to Mating Part	Yes
Keying to Mating Part	None
Lock to Mating Part	Yes
Mated Height	9.70mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold over Nickel
Material - Plating Termination	Tin over Nickel
Material - Resin	High Temperature Thermoplastic
Net Weight	622.000/mg
Number of Rows	1
Orientation	Vertical
PCB Locator	No
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	1.50mm
Pitch - Termination Interface	1.50mm
Plating min - Mating	0.203µm
Plating min - Termination	0.203µm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Robotic Placement	Vacuum Pick-Up Tape
Stackable	No
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Surface Mount
Electrical	
Current - Maximum per Contact	2.0A
Voltage - Maximum	100V AC (RMS)/DC

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ED/71/2019 (16 July 2019)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

505405 Series

Mates With

502578 CLIK-Mate Housing

Material Info

Reference - Drawing Numbers

Application Specification	AS-502578-001-001, AS-502578-002-001
Packaging Specification	SPK-505405-001-001
Product Specification	PS-505405-001-001
Sales Drawing	SD-505405-001, SD-505405-002, SD-505405-003, SD-505405-004

This document was generated on 11/18/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

505405-0760