

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

**Part Number:** [0003062023](#)  
**Status:** **Active**  
**Overview:** [Standard .062"+ and Standard .062" Pin and Socket Connector Systems](#)  
**Description:** [1.57mm Diameter Standard .062" Pin and Socket Plug Housing, 2 Circuits, without Mounting Ears, Natural](#)

**Documents:**

|                                |                                                               |
|--------------------------------|---------------------------------------------------------------|
| <a href="#">3D Model (PDF)</a> | <a href="#">Product Specification PS-02-06-001 (PDF)</a>      |
| <a href="#">Drawing (PDF)</a>  | <a href="#">Packaging Specification PK-1625-003-001 (PDF)</a> |
| <a href="#">3D Model</a>       | <a href="#">RoHS Certificate of Compliance (PDF)</a>          |

**Agency Certification**

|     |         |
|-----|---------|
| CSA | LR19980 |
| UL  | E29179  |

**General**

|                |                                                                                     |
|----------------|-------------------------------------------------------------------------------------|
| Product Family | Crimp Housings                                                                      |
| Series         | <a href="#">1625</a>                                                                |
| Application    | Power, Wire-to-Wire                                                                 |
| Comments       | Polarized to Mating Part                                                            |
| Overview       | <a href="#">Standard .062"+ and Standard .062" Pin and Socket Connector Systems</a> |
| Product Name   | Standard .062"                                                                      |
| UPC            | 800753615199                                                                        |

**Physical**

|                               |                |
|-------------------------------|----------------|
| Breakaway                     | No             |
| Circuits (maximum)            | 2              |
| Circuits Detail               | 1x2            |
| Color - Resin                 | Natural        |
| Flammability                  | 94V-2          |
| Gender                        | Plug           |
| Glow-Wire Capable             | No             |
| Keying to Mating Part         | None           |
| Lock to Mating Part           | Yes            |
| Material - Resin              | Nylon          |
| Net Weight                    | 0.790/g        |
| Number of Rows                | 1              |
| Packaging Type                | Bag            |
| Panel Mount                   | No             |
| Pitch - Mating Interface      | 3.68mm         |
| Pitch - Termination Interface | 3.68mm         |
| Polarized to Mating Part      | Yes            |
| Stackable                     | No             |
| Temperature Range - Operating | -40° to +105°C |

**Electrical**

|                               |      |
|-------------------------------|------|
| Current - Maximum per Contact | 5.0A |
|-------------------------------|------|

**Solder Process Data**


|                             |     |
|-----------------------------|-----|
| Lead-freeProcess Capability | N/A |
|-----------------------------|-----|

**Material Info**

|                    |          |
|--------------------|----------|
| Engineering Number | 1625-2P1 |
|--------------------|----------|

**Reference - Drawing Numbers**

|                         |                 |
|-------------------------|-----------------|
| Packaging Specification | PK-1625-003-001 |
| Product Specification   | PS-02-06-001    |

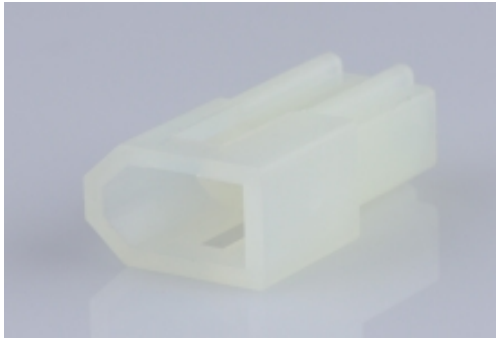

Series image - Reference only

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**China RoHS**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

|                 |               |
|-----------------|---------------|
| China ROHS      | Green Image   |
| ELV             | Not Relevant  |
| RoHS Phthalates | Not Contained |

**Search Parts in this Series**

[1625 Series](#)

**Mates With**

[03061022](#) , [03061023](#) , [03066023](#)

**Use With**

Female Crimp Terminals [1561](#) , [4559](#) , [4529](#) , [2190](#) , [2189](#) , [1787](#) , [1855](#) . Male Crimp Terminals [1560](#) , [1786](#) , [1854](#) . [1778](#) Male PC Tail Terminals. [1779](#) Female PC Tail Terminals

This document was generated on 08/30/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[03-06-2023](#)