

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0191930283

Status:

Active

Overview:

VersaKrimp Terminals and Splices

Description:

VersaKrimp Ring Tongue Terminal for 4 AWG Wire

Documents:


Drawing (PDF)

Product Specification PS-19902-011-001 (PDF)

Product Specification PS-19902-013-001 (PDF)

RoHS Certificate of Compliance (PDF)

|                              |                                    |
|------------------------------|------------------------------------|
| Agency Certification         |                                    |
| CSA                          | LR18689                            |
| UL                           | E32244                             |
| General                      |                                    |
| Product Family               | Ring and Spade Terminals           |
| Series                       | 19193                              |
| Crimp Quality Equipment      | Yes                                |
| Overview                     | VersaKrimp Terminals and Splices   |
| Product Name                 | VersaKrimp                         |
| Type                         | Ring                               |
| UPC                          | 800755051155                       |
| Physical                     |                                    |
| Barrel Type                  | Closed - Brazed                    |
| Insulation                   | None                               |
| Material - Plating Mating    | Tin                                |
| Net Weight                   | 14.025/g                           |
| Packaging Type               | Bag                                |
| Plating min - Mating         | 2.540µm                            |
| Plating min - Termination    | 2.540µm                            |
| Stud Size                    | 3/8" (M9)                          |
| Termination Interface: Style | Crimp or Compression               |
| Wire Size AWG                | 4                                  |
| Material Info                |                                    |
| Engineering Number           | F-369-38                           |
| Reference - Drawing Numbers  |                                    |
| Product Specification        | PS-19902-011-001, PS-19902-013-001 |
| Sales Drawing                | 191930254-000                      |

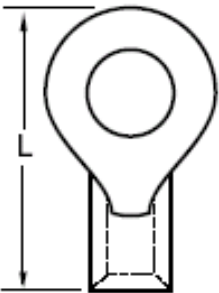

Series image - Reference only

|                                                               |               |
|---------------------------------------------------------------|---------------|
| EU ELV                                                        |               |
| Not Relevant                                                  |               |
| EU RoHS                                                       | China RoHS    |
| Compliant                                                     |               |
| REACH SVHC                                                    |               |
| Not Contained Per                                             |               |
| -ED/88/2018 (15                                               |               |
| January 2019)                                                 |               |
| Halogen-Free                                                  |               |
| Status                                                        |               |
| Not Relevant                                                  |               |
| For more information, please visit <a href="#">Contact US</a> |               |
| China ROHS                                                    | Not Relevant  |
| ELV                                                           | Not Relevant  |
| RoHS Phthalates                                               | Not Contained |

Search Parts in this Series

19193 Series

|                                                                                                                                                                                 |           |
|---------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|-----------|
| Application Tooling   <a href="#">FAQ</a>                                                                                                                                       |           |
| Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document. |           |
| Global                                                                                                                                                                          |           |
| Description                                                                                                                                                                     | Product # |
| Manual Putt Pump                                                                                                                                                                | 192860117 |
| Hydraulic System,                                                                                                                                                               |           |
| Die set required                                                                                                                                                                |           |
| Die Set (large) for                                                                                                                                                             | 192900007 |
| the HHLS Hydraulic                                                                                                                                                              |           |
| Crimper                                                                                                                                                                         |           |
| Hydraulic Dieless                                                                                                                                                               | 638161700 |
| Crimping Tool                                                                                                                                                                   |           |
| PremiumGrade Hand                                                                                                                                                               | 640013900 |
| Crimp Tool for 2-8                                                                                                                                                              |           |
| AWG Terminals                                                                                                                                                                   |           |
| Square “DIN” style                                                                                                                                                              | 640037870 |
| dies for 4 AWG                                                                                                                                                                  |           |

This document was generated on 08/04/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

19193-0283