

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0192120001](#)  
**Status:** **Active**  
**Overview:** [Wire Pins](#)  
**Description:** InsulKrimp Wire Pin Terminal for 12-10 AWG Wire

**Documents:**

[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)  
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR18689  
 UL E32244

**General**

Product Family Crimp Terminals  
 Series [19212](#)  
 Application Power, Wire-to-Component  
 Comments Pin Length 11.68mm  
 Crimp Quality Equipment Yes  
 Overview [Wire Pins](#)  
 Packaging Alternative [192120002](#) (Adhesive Tape on Reel)  
 Product Name Wire Pin  
 UPC 800753053298

**Physical**


Flammability 94V-0  
 Gender Male  
 Material - Metal Copper  
 Material - Plating Mating Tin  
 Net Weight 1.789/g  
 Packaging Type Bag  
 Plating min - Mating 1.016µm  
 Termination Interface: Style Crimp or Compression  
 Wire Insulation Diameter 6.35mm max.  
 Wire Size AWG 10, 12  
 Wire Size mm<sup>2</sup> N/A

**Material Info**

Engineering Number WP-2210X

**Reference - Drawing Numbers**

Product Specification PS-19902-011-001, PS-19902-013-001  
 Sales Drawing SD-19212-001-001

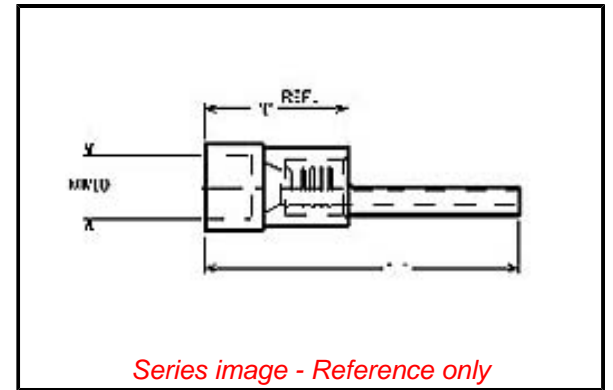

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
 D(2021)4569-DC (8  
 July 2021)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[19212 Series](#)

**Application Tooling | [FAQ](#)**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

**Description**

**Product #**

PremiumGrade  
 Hand Crimp Tool  
 for Avikrimp and  
 Insulkrimp Terminals  
 and Splices,  
 10-22 AWG and  
 6.0-0.5mm<sup>2</sup> (Rings,  
 Spades, Hooks,  
 Block Spades and  
 Flanged Spades)  
 PremiumGrade  
 Hand Crimp Tool for  
 Insulkrimp Terminals  
 and Splices, 10-22

[640010100](#)

[640010300](#)

AWG (Rings,  
Spades, Hooks,  
Block Spades and  
Flanged Spades)  
Crimp Head for the 640050100  
AT-200 Pneumatic  
Hand Tool  
Crimp Head for the 640050300  
AT-200 Pneumatic  
Hand Tool  
ServiceGrade Hand 640160036  
Crimp Tool for Field  
Repair only, for  
production use our  
PremiumGrade Tool

This document was generated on 08/26/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19212-0001](#)