

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0192900028

Status:

Active

Overview:

Application Tooling

Description:

Die Set (large) for the HHLS Hydraulic Crimper

Documents:

RoHS Certificate of Compliance (PDF)

General

Product Family

Series

Function

Geographic Area

Level of Automation

More Detailed Tech Information

Overview

Product Name

Tool Type

UPC

Warranty Disclaimer

Application Tooling

207122

Crimp

Global

Manual

applicationtooling@molex.com

Application Tooling

ETC

Crimp Module

800753111790

CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info


Engineering Number

HHL-K-170

Reference - Drawing Numbers

Application Tooling Documents

ATS-192900028-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

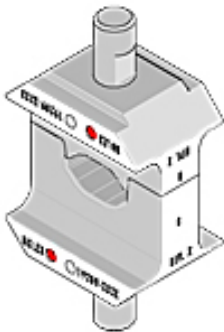

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

207122 Series

Use With

Molex HHLS Air Powered Hydraulic Crimper 12 Ton [192860058](#) , Manual Putt Pump Hydraulic System [192860117](#) , Electric Powered Hydraulic System [192861300](#)

Application Tooling Description	FAQ Product #
VersaKrimp Ring Tongue Terminal for 3/0 AWG Wire	191930354
VersaKrimp Ring Tongue Terminal for 3/0 AWG Wire	191930358
VersaKrimp Ring Tongue Terminal for 3/0 AWG Wire	191930360
VersaKrimp Ring Tongue Terminal for 3/0 AWG Wire	191930362
VersaKrimp Butt Splice for 3/0 AWG Wire	192050012

	VersaKrimp Parallel Splice for 3/0 AWG Wire	<u>192150049</u>
	Compression Style Ring Tongue Terminal for 3/0 AWG Wire, Stud Size 5/16" (M8), Plated	<u>192210246</u>
	Compression Style Ring Tongue Terminal for 3/0 AWG Wire, Stud Size 3/8" (M9), Plated	<u>192210247</u>
	Compression Style Ring Tongue Terminal for 3/0 AWG Wire, Stud Size 1/2" (M12), Plated	<u>192210248</u>
	Compression Style Ring Tongue Terminal for 3/0 AWG Wire, Stud Size 3/8" (M9), Unplated	<u>192210381</u>
	Compression Style Ring Tongue Terminal for 3/0 AWG Wire, Stud Size 1/2" (M12), Unplated	<u>192210401</u>
	Compression Style Ring Tongue Terminal for 3/0 AWG Wire, Stud Size 5/16" (M8), Unplated	<u>192210402</u>
	Compression Style Ring Tongue Terminal for 3/0 AWG Wire, Stud Size 1/4" (M6), Unplated	<u>192210478</u>
	Compression Style Ring Tongue Terminal for 3/0 AWG Wire, Stud Size 1/4" (M6), Plated	<u>192210570</u>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

19290-0028