

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0387406103

Status:


Active

Overview:

Beau Barrier Strips

Description:

11.11mm Pitch Beau PCB Fixed Mount Barrier Terminal Strip, Low Profile, 300V, 3 Circuits

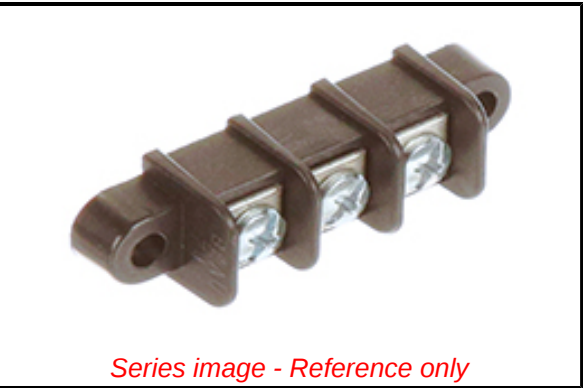

Series image - Reference only

Documents:	
3D Model (PDF)	Product Specification PS-38730-001-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
3D Model	

General	
Product Family	Terminal Blocks
Series	38740
Application	N/A
Component Type	One Piece
Overview	Beau Barrier Strips
Product Name	Fixed Mount Barrier
Type	Barrier Strip
UPC	800756319384
Physical	
Circuits (Loaded)	3
Circuits (maximum)	3
Color - Resin	Black
Entry Angle	Horizontal
Lock to Mating Part	No
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester Alloy
Number of Rows	1
Orientation	Horizontal
PC Tail Length	5.50mm
PCB Retention	Yes
PCB Thickness - Recommended	2.40mm
Panel Mount	No
Pitch - Mating Interface	11.11mm
Pitch - Termination Interface	11.11mm
Polarized to Mating Part	No
Stackable	No
Temperature Range - Operating	-40° to +130°C
Wire Size AWG	14, 16, 18, 20, 22
Wire Size mm²	0.50-1.50
Electrical	
Current - Maximum per Contact	15.0A
Voltage - Maximum	300V
Solder Process Data	
Lead-freeProcess Capability	WAVE
Material Info	
Engineering Number	74503
Reference - Drawing Numbers	
Product Specification	PS-38730-001-001
Sales Drawing	SD-38740-002

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

38740 Series

This document was generated on 07/27/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[38740-6103](#)