

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395005607

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

3.50mm Pitch Eurostyle Horizontal Plug, with Standard Imprinting, Green Housing, Gold (Au) Plated, 7 Circuits

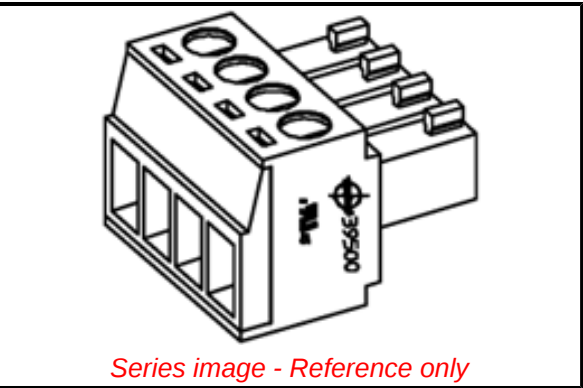

Documents:

3D Model

3D Model (PDF)

Drawing (PDF)

Product Specification PS-39500-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

|                               |                           |
|-------------------------------|---------------------------|
| Agency Certification          |                           |
| UL                            | E48521                    |
| General                       |                           |
| Product Family                | Terminal Blocks           |
| Series                        | 39500                     |
| Application                   | N/A                       |
| Comments                      | with Standard Imprinting  |
| Component Type                | Plug                      |
| Overview                      | Eurostyle Terminal Blocks |
| Product Name                  | ESE, Eurostyle Pluggable  |
| Type                          | Euro Block                |
| UPC                           | 822350429146              |
| Physical                      |                           |
| Circuits (Loaded)             | 7                         |
| Entry Angle                   | Vertical                  |
| Lock to Mating Part           | None                      |
| Number of Rows                | 1                         |
| Orientation                   | Horizontal                |
| Panel Mount                   | No                        |
| Pitch - Mating Interface      | 3.50mm                    |
| Pitch - Termination Interface | 3.50mm                    |
| Polarized to Mating Part      | Yes                       |
| Stackable                     | No                        |
| Temperature Range - Operating | -40° to +105°C            |
| Wire Size AWG                 | 16, 18, 20, 22, 24, 30    |
| Wire Size mm²                 | 0.05-1.50                 |
| Electrical                    |                           |
| Current - Maximum per Contact | 8.0A                      |
| Voltage - Maximum             | 300V                      |
| Material Info                 |                           |
| Reference - Drawing Numbers   |                           |
| Product Specification         | PS-39500-001-001          |
| Sales Drawing                 | SD-39500-001              |

|                                                               |              |
|---------------------------------------------------------------|--------------|
| EU ELV                                                        |              |
| Not Relevant                                                  |              |
| EU RoHS                                                       | China RoHS   |
| Not Reviewed                                                  |              |
| REACH SVHC                                                    |              |
| Not Reviewed                                                  |              |
| Halogen-Free                                                  |              |
| Status                                                        |              |
| Not Reviewed                                                  |              |
| For more information, please visit <a href="#">Contact US</a> |              |
| China ROHS                                                    | Not Relevant |
| ELV                                                           | Not Relevant |
| RoHS Phthalates                                               | Not Reviewed |

Search Parts in this Series

39500 Series

Mates With

39501 Vertical PCB Header, 39502 Horizontal PCB Header, Most 3.50mm Pitch Industry Standard PCB Headers

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39500-5607](#)