

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395105710

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

3.81mm Pitch Eurostyle Horizontal Plug, with Reverse Imprinting, Green Housing, Gold (Au) Plated, 10 Circuits

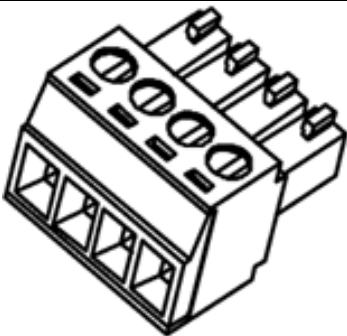

Series image - Reference only

Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

[Product Specification PS-39500-001-001 \(PDF\)](#)

Agency Certification

UL

E48521

General

Product Family

Terminal Blocks

Series

39510

Application

N/A

Comments

with Reverse Imprinting

Component Type

Plug

Overview

Eurostyle Terminal Blocks

Product Name

ESE, Eurostyle Pluggable

Type

Euro Block

UPC

822350688789

Physical

Circuits (Loaded)

10

Entry Angle

Vertical

Lock to Mating Part

None

Number of Rows

1

Orientation

Horizontal

Panel Mount

No

Pitch - Mating Interface

3.81mm

Pitch - Termination Interface

3.81mm

Polarized to Mating Part

Yes

Stackable

No

Temperature Range - Operating

-40° to +105°C

Wire Size AWG

16, 18, 20, 22, 24

Wire Size mm²

0.20-1.31

Electrical

Current - Maximum per Contact

8.0A

Voltage - Maximum

300V

Material Info

Reference - Drawing Numbers

Product Specification

PS-39500-001-001

Sales Drawing

SD-39510-001

EU ELV

Not Relevant

EU RoHS

Not Reviewed

China RoHS

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

39510 Series

Mates With

Most 3.81mm Pitch Industry Standard PCB Headers, [39511](#) Vertical PCB Header, [39512](#) Horizontal PCB Header

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

39510-5710