

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395132307

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

3.81mm Pitch Eurostyle Vertical Plug, with Standard Imprinting, Rear Wire Entry, 7 Circuits

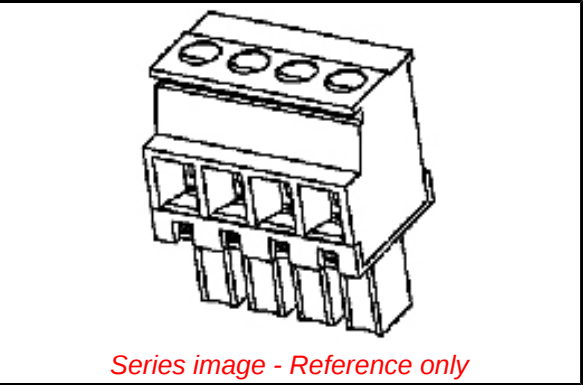

Documents:

Drawing (PDF)

Product Specification PS-39500-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification		
UL		E48521
General		
Product Family		Terminal Blocks
Series		39513
Application		N/A
Comments		with Standard Imprinting Rear Wire Entry
Component Type		Plug
Overview		Eurostyle Terminal Blocks
Product Name		ESE, Eurostyle Pluggable
Type		Euro Block
UPC		822350467070
Physical		
Circuits (Loaded)		7
Entry Angle		Horizontal
Lock to Mating Part		None
Number of Rows		1
Orientation		Vertical
Panel Mount		No
Pitch - Mating Interface		3.81mm
Pitch - Termination Interface		3.81mm
Polarized to Mating Part		Yes
Stackable		No
Temperature Range - Operating		-40° to +105°C
Wire Size AWG		16, 18, 20, 22, 24, 26, 28, 30
Wire Size mm²		0.05-1.31
Electrical		
Current - Maximum per Contact		8.0A
Voltage - Maximum		300V
Material Info		
Reference - Drawing Numbers		
Product Specification		PS-39500-001-001
Sales Drawing		SD-39513-002

EU ELV

Not Relevant

EU RoHS

Not Reviewed

China RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit

Contact US

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

39513 Series

Mates With

Most 3.81mm Pitch Industry Standard PCB Headers, 39511 Vertical PCB Header, 39512 Horizontal PCB Header

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

39513-2307