

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395305624

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

5.08mm Pitch Eurostyle Horizontal Plug, with Standard Imprinting, Green Housing, Gold (Au) Plated, 24 Circuits

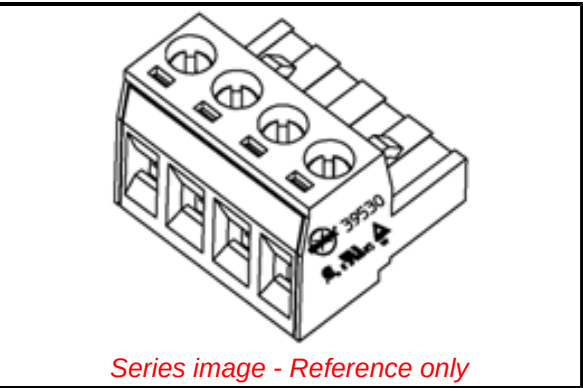

Documents:

[Drawing \(PDF\)](#)

[Product Specification PS-39500-001-001 \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
UL	E48521
General	
Product Family	Terminal Blocks
Series	39530
Application	N/A
Comments	with Standard Imprinting
Component Type	Plug
Overview	Eurostyle Terminal Blocks
Product Name	ESE, Eurostyle Pluggable
Type	Euro Block
UPC	822350539654
Physical	
Circuits (Loaded)	24
Entry Angle	Vertical
Lock to Mating Part	Yes
Number of Rows	1
Orientation	Horizontal
Panel Mount	No
Pitch - Mating Interface	5.08mm
Pitch - Termination Interface	5.08mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	12, 14, 16, 18, 20, 22, 24, 26
Wire Size mm²	0.13-3.31
Electrical	
Current - Maximum per Contact	18.0A
Voltage - Maximum	300V
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Product Specification	PS-39500-001-001
Sales Drawing	SD-39530-001-001, SD-39530-001-002

EU ELV

Not Relevant

EU RoHS

Not Reviewed

China RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit

Contact US

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

39530 Series

Mates With

39531 Vertical PCB Header, 39532 Horizontal PCB Header, 39538 Dual Level PCB Header, Open Ends, Most 5.08mm Pitch Industry Standard PCB Headers

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

39530-5624