

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0395345715

Status: Active

Overview: Eurostyle Terminal Blocks

Description: 5.08mm Pitch Eurostyle Horizontal Plug, with Retention Screws and Reverse Imprinting, Green Housing, Gold (Au) Plated, 15 Circuits

Documents:

[3D Model](#) [Product Specification PS-39500-001-001 \(PDF\)](#)

[3D Model \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

[Drawing \(PDF\)](#)

Agency Certification

UL E48521

General

Product Family Terminal Blocks

Series 39534

Application N/A

Comments with Reverse Imprinting

Component Type Plug

Overview Eurostyle Terminal Blocks

Product Name ESE, Eurostyle Pluggable

Type Euro Block

UPC 822350486668

Physical

Circuits (Loaded) 15

Entry Angle Vertical

Lock to Mating Part Yes

Number of Rows 1

Orientation Horizontal

Panel Mount No

Pitch - Mating Interface 5.08mm

Pitch - Termination Interface 5.08mm

Polarized to Mating Part Yes

Stackable No

Temperature Range - Operating -40° to +105°C

Wire Size AWG 12, 14, 16, 18, 20, 22, 24, 26

Wire Size mm² 0.13-3.31

Electrical

Current - Maximum per Contact 18.0A

Voltage - Maximum 300V

Solder Process Data


Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers

Product Specification PS-39500-001-001

Sales Drawing SD-39534-001

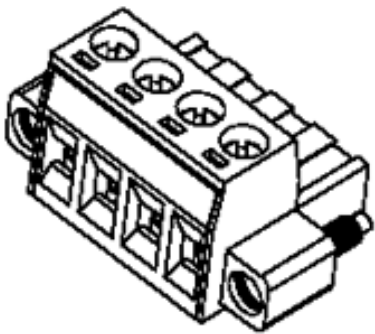

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

39534 Series

Mates With

Most 5.08mm Pitch Industry Standard PCB Headers, [39535](#) Vertical PCB Header with Threaded Retention Inserts, [39536](#) Horizontal PCB Header with Threaded Retention Inserts

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

39534-5715