

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395372314

Status:


Active

Overview:

Eurostyle Terminal Blocks

Description:

5.08mm Pitch Eurostyle Vertical Plug, with Retention Screws and Standard Imprinting, Rear Wire Entry, 14 Circuits

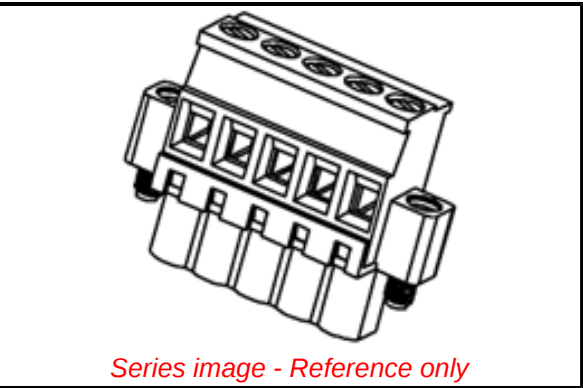

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

|                               |                                          |
|-------------------------------|------------------------------------------|
| General                       |                                          |
| Product Family                | Terminal Blocks                          |
| Series                        | 39537                                    |
| Application                   | N/A                                      |
| Comments                      | with Standard Imprinting Rear Wire Entry |
| Component Type                | Plug                                     |
| Overview                      | Eurostyle Terminal Blocks                |
| Product Name                  | ESE, Eurostyle Pluggable                 |
| Type                          | Euro Block                               |
| UPC                           | 822350697040                             |
| Physical                      |                                          |
| Circuits (Loaded)             | 14                                       |
| Entry Angle                   | Horizontal                               |
| Lock to Mating Part           | Yes                                      |
| Number of Rows                | 1                                        |
| Orientation                   | Vertical                                 |
| Panel Mount                   | No                                       |
| Pitch - Mating Interface      | 5.08mm                                   |
| Pitch - Termination Interface | 5.08mm                                   |
| Polarized to Mating Part      | Yes                                      |
| Stackable                     | No                                       |
| Temperature Range - Operating | -40° to +105°C                           |
| Wire Size AWG                 | 12, 14, 16, 18, 20, 22, 24, 26           |
| Wire Size mm²                 | 0.13-3.31                                |
| Electrical                    |                                          |
| Current - Maximum per Contact | 18.0A                                    |
| Voltage - Maximum             | 300V                                     |
| Solder Process Data           |                                          |
| Lead-freeProcess Capability   | N/A                                      |
| Material Info                 |                                          |
| Reference - Drawing Numbers   |                                          |
| Sales Drawing                 | SD-39537-002                             |

|                                                               |              |
|---------------------------------------------------------------|--------------|
| EU ELV                                                        |              |
| Not Relevant                                                  |              |
| EU RoHS                                                       | China RoHS   |
| Not Reviewed                                                  |              |
| REACH SVHC                                                    |              |
| Not Reviewed                                                  |              |
| Halogen-Free                                                  |              |
| Status                                                        |              |
| Not Reviewed                                                  |              |
| For more information, please visit <a href="#">Contact US</a> |              |
| China ROHS                                                    | Not Reviewed |
| ELV                                                           | Not Relevant |
| RoHS Phthalates                                               | Not Reviewed |

Search Parts in this Series

39537 Series

Mates With

Most 5.08mm (.200") Pitch Industry Standard PCB Headers, 39535 Vertical PCB Header with Threaded Retention Inserts, 39536 Horizontal PCB Header with Threaded Retention Inserts

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39537-2314](#)