

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0399400209

Status: Active

Overview: Eurostyle Terminal Blocks

Description: 5.08mm Pitch Beau EuroMate Pluggable PCB Terminal Block, Dual Level, 90° Wire Entry, 9 Circuits

Documents:

[3D Model](#) [Product Specification PS-39940-001-001 \(PDF\)](#)

[3D Model \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

[Drawing \(PDF\)](#)

Agency Certification

UL E48521

General

Product Family Terminal Blocks

Series 39940

Application N/A

Comments Gold plating available

Component Type Plug

Overview Eurostyle Terminal Blocks

Product Name EuroMate Pluggable

Type Euro Block

UPC 800756372006

Physical

Circuits (Loaded) 9

Color - Resin Black

Entry Angle Horizontal

Flammability 94V-0

Lock to Mating Part None

Material - Resin Nylon

Number of Rows 2

Orientation Vertical

Panel Mount No

Pitch - Mating Interface 5.08mm

Pitch - Termination Interface 5.08mm

Polarized to Mating Part Yes

Stackable No

Temperature Range - Operating 130°C

Termination Interface: Style Screw or Lug

Wire Size AWG 12, 14, 16, 18, 20, 22

Wire Size mm² 0.50-2.50

Electrical

Current - Maximum per Contact 15.0A

Voltage - Maximum 300V


Material Info

Engineering Number 940809

Reference - Drawing Numbers

Product Specification PS-39940-001-001

Sales Drawing SD-39940-004

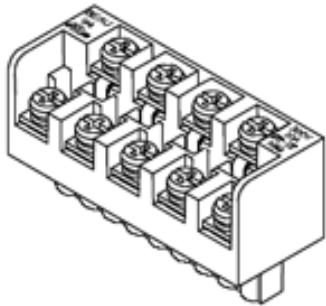

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

39940 Series

Mates With

395310009 , 395311009 , 395320009 , 395321009

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39940-0209](#)