

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0423753505](#)
Status: **Active**
Description: KK 100 Hdr Assy Bkwy 08 Ckt

Documents:

Drawing (PDF)	Packaging Specification PK-40873-0043-001 (PDF)
Product Specification PS-10-07-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR19980
UL	E29179

Application tooling part link

Application Tooling Part Link	11-20-1230
-------------------------------	------------

General

Product Family	PCB Headers
Series	42375
Product Name	KK 254
UPC	822348776962

Physical

Flammability	94V-0
Net Weight	0.875/g

Electrical

Voltage - Maximum	500V
-------------------	------


Solder Process Data

Duration at Max. Process Temperature (seconds)	005
Lead-freeProcess Capability	WAVE
Max. Cycles at Max. Process Temperature	001
Process Temperature max. C	235

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-40873-0043-001
Product Specification	PS-10-07-001
Sales Drawing	SD-42375-001-001

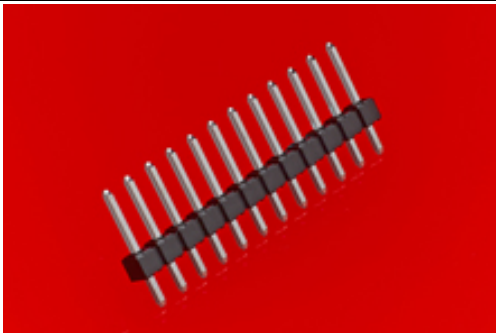

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[42375](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

42375-3505