


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0510891005
Status: Active
Description: 2.00mm Pitch Mi II System Wire-to-Board Crimp Housing, Dual Row, 10 Circuits, Gray

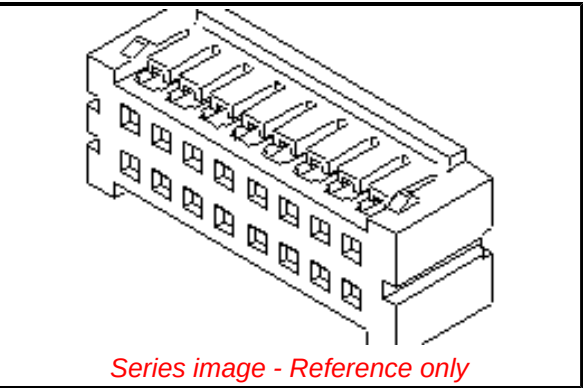

Documents:
3D Model Product Specification PS-51089-005-001 (PDF)
Drawing (PDF) Application Specification AS-52484-001-001 (PDF)
Product Specification PS-51089-001 (PDF) RoHS Certificate of Compliance (PDF)

Agency Certification
CSA LR19980
UL E29179

General
Product Family Crimp Housings
Series 51089
Application Signal, Wire-to-Board
Product Name Mi II
UPC 800753688230

Physical
Circuits (maximum) 10
Color - Resin Gray
Flammability 94V-0
Gender Receptacle
Glow-Wire Capable No
Lock to Mating Part Yes
Material - Resin Polyester
Net Weight 507.100/mg
Number of Rows 2
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 2.00mm
Stackable No
Temperature Range - Operating -40° to +105°C

Material Info

Reference - Drawing Numbers
Application Specification AS-52484-001-001
Product Specification PS-51089-001, PS-51089-005-001
Sales Drawing SD-51089-**05

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
ED/61/2018 (27 June
2018)
Halogen-Free
Status
Not Low-Halogen
**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series
[51089](#) Series

Mates With
[53313](#) , [53314](#)

Use With
[50212](#) Crimp Terminals

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

51089-1005