

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0511460200

Status:


Active

Overview:

PanelMate™ Wire-to-Board Connector System

Description:

1.25mm Pitch PanelMate Wire-to-Board Receptacle Housing, Ultra Low Profile, 2 Circuits

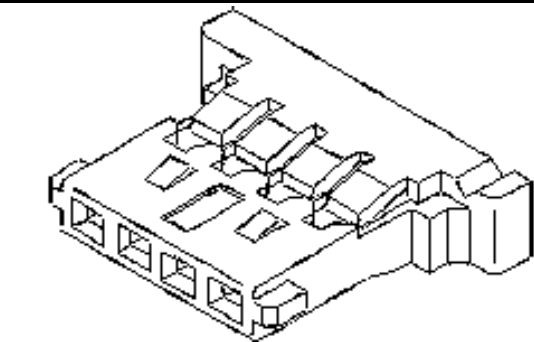

Series image - Reference only

Documents:	
3D Model	Product Specification PS-51146-010-001 (PDF)
Drawing (PDF)	Packaging Specification 511469200-200 (PDF)
Product Specification PS-51146-008-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E107635
General	
Product Family	Crimp Housings
Series	51146
Application	Power, Wire-to-Board
MolexKits	Yes
Overview	PanelMate™ Wire-to-Board Connector System
Product Name	PanelMate
UPC	800754319980
Physical	
Circuits (maximum)	2
Color - Resin	Natural
Flammability	94V-0
Gender	Receptacle
Glow-Wire Compliant	No
Net Weight	26.900/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	1.25mm
Temperature Range - Operating	-40°C to +85°C
Material Info	
Reference - Drawing Numbers	
Packaging Specification	511469200-200
Product Specification	PS-51146-008-001, PS-51146-010-001
Sales Drawing	SD-51146-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ED/30/2017 (7 July 2017)	
Halogen-Free	
Status	
Not Low-Halogen	
Need more information on product environmental compliance?	
Email productcompliance@molex.com	
Please visit the Contact Us section for any non-product compliance questions.	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[51146](#) Series

Mates With

[53780](#)

Use With

[50641](#) Crimp Terminal . [50753](#) Crimp Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[51146-0200](#)