


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0511461200](#)
Status: **Active**
Overview: PanelMate™ Wire-to-Board Connector System
Description: 1.25mm Pitch PanelMate™ Wire-to-Board Receptacle Housing, Ultra Low Profile, 12 Circuits

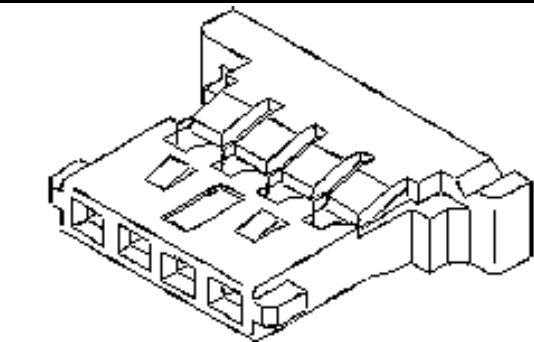

Series image - Reference only

Documents:
[3D Model](#) [Product Specification PS-51146-010-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [Packaging Specification 511469200-200 \(PDF\)](#)
[Product Specification PS-51146-008-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR19980
UL E107635

General

Product Family Crimp Housings
Series [51146](#)
Application Power, Wire-to-Board
Overview [PanelMate™ Wire-to-Board Connector System](#)
Product Name PanelMate™
UPC 800753324329

Physical

Circuits (maximum) 12
Color - Resin Natural
Flammability 94V-0
Gender Receptacle
Glow-Wire Compliant No
Net Weight 102.200/mg
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 1.25mm
Temperature Range - Operating -40°C to +85°C

Material Info

Reference - Drawing Numbers

Packaging Specification 511469200-200
Product Specification PS-51146-008-001, PS-51146-010-001
Sales Drawing SD-51146-001

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July
2017)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series

[51146](#) Series

Mates With

[53780](#)

Use With

[50641](#) Crimp Terminal . [50753](#) Crimp
Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[51146-1200](#)