


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0511462000

Status: Active

Overview: PanelMate™ Wire-to-Board Connector System

Description: 1.25mm Pitch PanelMate™ Wire-to-Board Receptacle Housing, Ultra Low Profile, 20 Circuits

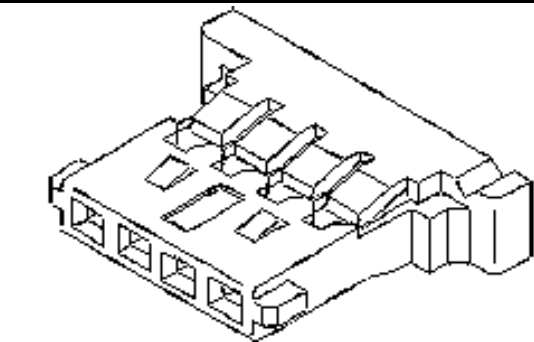

Series image - Reference only

Documents:

3D Model	Product Specification PS-51146-011-001 (PDF)
Drawing (PDF)	Packaging Specification 511469200-200 (PDF)
Product Specification PS-51146-010-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR19980
UL	E107635

General

Product Family	Crimp Housings
Series	51146
Application	Power, Wire-to-Board
Overview	PanelMate™ Wire-to-Board Connector System
Product Name	PanelMate™
UPC	800753683495

Physical

Circuits (maximum)	20
Color - Resin	Natural
Flammability	94V-0
Gender	Receptacle
Glow-Wire Compliant	No
Net Weight	162.400/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	1.25mm
Temperature Range - Operating	-40°C to +85°C

Material Info

Reference - Drawing Numbers

Packaging Specification	511469200-200
Product Specification	PS-51146-010-001, PS-51146-011-001
Sales Drawing	SD-51146-001

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July
2017)

Halogen-Free

Status

Not Low-Halogen

Need more information on product
environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

51146 Series

Mates With

53780

Use With

50641 Crimp Terminal . 50753 Crimp
Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[51146-2000](#)