

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0530480610

Status:

Active

Overview:

PicoBlade Connector System

Description:

1.25mm Pitch, PicoBlade PCB Header, Single Row, Right-Angle, Through Hole, Tin (Sn) Plating, Friction Lock, 6 Circuits, Tray, 2.30mm PC Tail Length

Documents:

- Drawing (PDF)

3D Model

2D Drawing (DXF)

2D Drawing DXF (PDF)

3D Model (PDF)
- Product Specification 510211010-PS-000 (PDF)

Product Specification PS-51021-010-001 (PDF)

Application Specification 510210000-AS-000 (PDF)

Packaging Specification SPK-53048-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

UL

E29179

General

Product Family

Series

Application

Current Derating Order No

Overview

Product Name

UPC

PCB Headers

53048

Signal, Wire-to-Board

987651-3691

PicoBlade Connector System

PicoBlade

800753750203

Physical

Breakaway

Circuits (Loaded)

Circuits (maximum)

Color - Resin

Durability (mating cycles max)

First Mate / Last Break

Glow-Wire Capable

Guide to Mating Part

Keying to Mating Part

Lock to Mating Part

Mated Height

Material - Plating Mating

Material - Plating Termination

Material - Resin

Net Weight

Number of Rows

Orientation

PC Tail Length

PCB Locator

PCB Retention

PCB Thickness - Recommended

Packaging Type

Pitch - Mating Interface

Polarized to PCB

Shrouded

Stackable

Temperature Range - Operating

Termination Interface: Style

No

6

6

Natural

30

No

No

No

None

Yes

3.50mm

Tin

Tin

Nylon

153.200/mg

1

Right Angle

2.30mm

No

None

0.80mm

Tray

1.25mm

No

Fully

No


-40° to +85°C

Through Hole

Electrical

Current - Maximum per Contact

1.0A

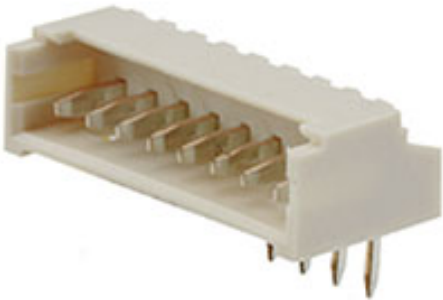

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

53048 Series

Mates With

PicoBlade Housing [51021](#)
PicoBlade
Cable Assembly [15134](#)

Voltage - Maximum

125V

Material Info

Reference - Drawing Numbers

Application Specification

510210000-AS-000

Packaging Specification

SPK-53048-001-001

Product Specification

510211010-PS-000, PS-51021-010-001

Sales Drawing

530480001-SD-000

This document was generated on 12/24/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[53048-0610](#)