

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0579158001](#)
Status: **Active**
Description: 2.50mm Pitch Wire-to-Board Terminal, 2.30 to 2.80mm Strip Length, Phosphor Bronze

Documents:

Drawing (PDF)	Product Specification PS-68426-001-001 (PDF)
Product Specification PS-35572-001 (PDF)	Packaging Specification PK-57915-001-001 (PDF)
Product Specification PS-49549-002-001 (PDF)	RoHS Certificate of Compliance (PDF)

General

Product Family	Crimp Terminals
Series	57915
Application	Signal, Wire-to-Board, Wire-to-Wire
Crimp Quality Equipment	Yes
Product Name	N/A
UPC	800755993363


Physical

Gender	Female
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.066/g
Packaging Type	Reel
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.15-1.80mm
Wire Size AWG	22, 24, 26, 28
Wire Size mm²	N/A

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-57915-001-001
Product Specification	PS-35572-001 , PS-49549-002-001 , PS-68426-001-001
Sales Drawing	SD-57915-001

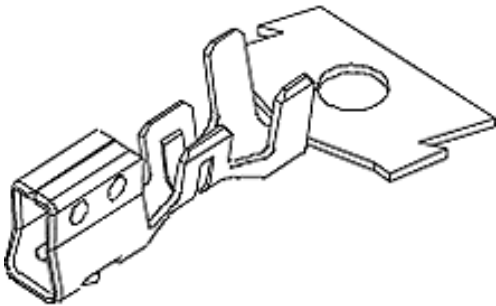

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per
-ED/88/2018 (15
January 2019)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[57915 Series](#)

Use With

[35572](#)

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Hand Crimp Tool for 2.50mm Wire-to-Board Crimp Terminals	638238600
T2 Terminator Die	638505100
FineAdjust Applicator	638605100

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[57915-8001](#)