

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0638120000](#)  
**Status:** **Active**  
**Overview:** [Application Tooling](#)  
**Description:** Insertion Tool for KK 2.54mm Terminals, 22-30 AWG

**Documents:**  
[RoHS Certificate of Compliance \(PDF\)](#)


**General**

|                                |   |
|--------------------------------|---|
| Product Family                 | Application Tooling   |
| Series                         | 207121  |
| Comments                       | <p style="margin-top: 0; margin-bottom: 0">See Tooling Specification (PDF) Above</li><li><p style="margin-top: 0; margin-bottom: 0">To be used with KK 2.54mm center series into all KK 2.54mm housings. </li></ul>   |
| Function                       | Insertion   |
| Geographic Area                | Global  |
| Level of Automation            | Manual  |
| More Detailed Tech Information | <a href="mailto:applicationtooling@molex.com">applicationtooling@molex.com</a>  |
| Overview                       | <a href="#">Application Tooling</a>   |
| Product Name                   | N/A   |
| Tool Type                      | Insertion Hand Tool   |
| UPC                            | 800754356992  |
| Warranty Disclaimer            | CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified. |

**Material Info**

**Reference - Drawing Numbers**  
[Application Tooling Documents](#)

ATS-638120000-001, TM-638000029-001, TM-638000029CN-001, TM-638000029DE-001, TM-638000029FR-001, TM-638000029IT-001, TM-638000029JP-001, TM-638000029KR-001, TM-638000029MY-001, TM-638000029PL-001, TM-638000029RU-001, TM-638000029SK-001, TM-638000029SP-001, TM-638000029TH-001, TM-638000029TW-001, TM-638000029VN-001

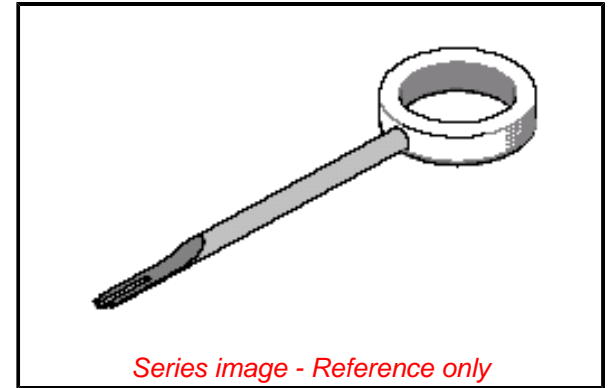

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Relevant**

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[207121 Series](#)

**Application Tooling** | **FAQ**  
**Description** | **Product #**

|   |                         |
|---|-------------------------|
| KK 254 Cat Ear Crimp Terminal 4809, 22-30 AWG, Hot Tin Dip, 2.20mm Insulation Crimp, Reel | <a href="#">8500030</a> |
| KK 254 Cat Ear Crimp Terminal 4809, 22-30 AWG, Hot Tin Dip, Reel                          | <a href="#">8500031</a> |
| KK 254 Cat Ear Crimp Terminal 4809, 22-30 AWG, Hot Tin Dip, Bag                           | <a href="#">8500032</a> |
| KK 254 Crimp Terminal, 22-30 AWG, Hot Tin (Sn) Dip Plating                                | <a href="#">8500113</a> |
| KK 254 Crimp Terminal 4809, 22-30 AWG, Hot Tin Dip, Reel                                  | <a href="#">8500135</a> |

|  |                |
|--|----------------|
| KK 254 Crimp<br>Terminal 6459,<br>22-30 AWG, Reel,<br>Phosphor Bronze Tin<br>(Sn)                                  | <u>8520101</u> |
| KK 254 Crimp<br>Terminal 6459,<br>22-30 AWG, Bag,<br>Phosphor Bronze Tin<br>(Sn)                                   | <u>8520123</u> |
| KK 254 Crimp<br>Terminal, 22-30<br>AWG, Reel,<br>Selective Gold (Au),<br>Nickel (Ni) Under<br>Plating              | <u>8550101</u> |
| KK 254 Crimp<br>Terminal, 22-30<br>AWG, Bag, Selective<br>Gold (Au), Nickel (Ni)<br>Under Plating                  | <u>8550102</u> |
| KK 254 Crimp<br>Terminal 4809, 22-30<br>AWG, Selective Gold<br>(Au), Reel  | <u>8550110</u> |
| KK 254 Cat Ear<br>Crimp Terminal<br>4809, 22-30 AWG,<br>Selective Gold, Reel                                       | <u>8550112</u> |
| KK High Pressure<br>Crimp Terminal,<br>Female, 24-30<br>AWG, Brass, 0.38µm<br>Selective Gold (Au)<br>Plating, Reel | <u>8550124</u> |
| KK 254 Crimp<br>Terminal, 22-30<br>AWG, Bag, Selective<br>Gold (Au), Nickel (Ni)<br>Under Plating                  | <u>8550131</u> |
| KK 254 Crimp<br>Terminal, 22-30<br>AWG, Reel, Gold<br>(Au), Nickel (Ni)<br>Under Plating                           | <u>8560109</u> |
| KK 254 Crimp<br>Terminal 4809, 22-30<br>AWG, Selective Gold<br>(Au), Reel  | <u>8560120</u> |
| KK 254 Cat Ear<br>Crimp Terminal<br>41572, Reel Tin (Sn)   | <u>8650804</u> |
| KK 254 Cat Ear<br>Crimp Terminal<br>41572, Bag Tin (Sn)  | <u>8650805</u> |
| KK 254 Crimp<br>Terminal 6459,<br>22-30 AWG, Reel,<br>Phosphor Bronze<br>Gold (Au)                                 | <u>8650813</u> |
| KK 254 Crimp<br>Terminal 6459,<br>22-30 AWG, Bag,<br>Phosphor Bronze<br>Gold (Au)                                  | <u>8650814</u> |

|   |                  |
|---|------------------|
| KK 254 Crimp<br>Terminal 6459,<br>22-30 AWG, Reel,<br>Phosphor Bronze<br>Selective Gold (Au)                          | <u>8650815</u>   |
| KK 254 Crimp<br>Terminal 6459,<br>22-30 AWG, Bag,<br>Phosphor Bronze<br>Selective Gold (Au)                           | <u>8650816</u>   |
| KK Cat Ear Crimp<br>Terminal 5159,<br>22-28 AWG, Reel,<br>Phosphor Bronze,<br>Tin (Sn) Plating                        | <u>8700048</u>   |
| KK Cat Ear Crimp<br>Terminal 5159,<br>22-28 AWG, Bag,<br>Phosphor Bronze,<br>Tin (Sn) Plating                         | <u>8700049</u>   |
| KK Cat Ear Crimp<br>Terminal 5159, 22-28<br>AWG, Reel, Brass,<br>Tin (Sn) over Copper<br>Plating                      | <u>8700064</u>   |
| KK Cat Ear Crimp<br>Terminal 5159, 22-28<br>AWG, Bag, Brass,<br>Tin (Sn) over Copper<br>Plating                       | <u>8700069</u>   |
| KK 254 Crimp<br>Terminal, 22-28<br>AWG, 0.35µm Gold<br>(Au), Nickel (Ni)<br>Under-Plate, Brass,<br>Loose              | <u>39000377</u>  |
| KK 254 Crimp<br>Terminal, 22-28<br>AWG, 0.35µm<br>Gold (Au), Nickel<br>(Ni) Under-Plate,<br>Phosphor Bronze,<br>Loose | <u>39000381</u>  |
| KK High Pressure<br>Crimp Terminal,<br>Female, 24-30 AWG,<br>Brass, 2.54µm Tin<br>(Sn) Plating, Bag                   | <u>469990101</u> |
| KK High Pressure<br>Crimp Terminal,<br>Female, 24-30 AWG,<br>Brass, 2.54µm Tin<br>(Sn) Plating, Reel                  | <u>50291900</u>  |
| MINI KK TERM<br>UNPLATED  | <u>8088999</u>   |

This document was generated on 11/02/2021

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[63812-0000](#)