

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0638850400

Status:

Active

Overview:

Application Tooling

Description:

Mini-Mac Applicator

Documents:

RoHS Certificate of Compliance (PDF)


General	
Product Family	Application Tooling
Series	207127
Comments	The Molex Tape Applicator requires an industry standard crimp press with a 4way air like the Molex TM-3000: 638017200 , 638017300 , and the Molex TM-4000: 638017600
Function	Crimp
Geographic Area	Global
Level of Automation	Automatic, Semi-Automatic
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	Mini-Mac
Tool Type	Applicator
UPC	822348748983
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Reference - Drawing Numbers

Application Tooling Documents

638850400-001, TM-638800000-001, TM-638800000SP-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

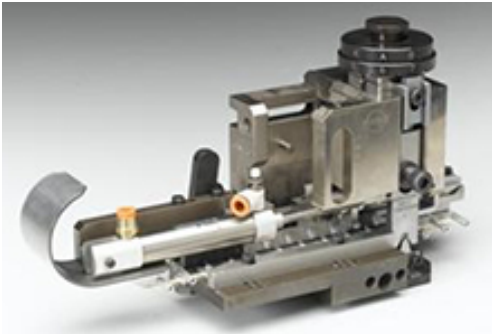

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Relevant	
REACH SVHC	
Not Relevant	
Halogen-Free	
Status	
Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Relevant

Search Parts in this Series

207127 Series

Use With

Molex TM-3000: [638017200](#) , [638017300](#) , Molex TM-4000: [638017600](#) , and Most Industry Standard Presses or Wire Process Machines

Application Tooling Description	FAQ Product #
InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire	190700061
InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire	190700064
InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire	190700066
InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire	190700070
InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire	190700072

InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire, Tape	<u>190700076</u>
InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire	<u>190700079</u>
InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire	<u>190700084</u>
InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire	<u>190700087</u>
InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire	<u>190700092</u>
InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire	<u>190700100</u>
InsulKrimp Ring Tongue Terminal for 14-16 AWG Wire	<u>190700104</u>
Avikrimp Ring Tongue Terminal for 14 to 16 AWG Wire, Stud Size 3/8" (M9), Length 31.12mm, Mylar Tape Carrier	<u>190730060</u>
Avikrimp Ring Tongue Terminal for 14 to 16 AWG Wire, Stud Size 5/16" (M8), Length 31.12mm, Mylar Tape Carrier	<u>190730062</u>
Avikrimp Ring Tongue Terminal for 14 to 16 AWG Wire, Stud Size 4 (M2.6), Length 20.32mm, Mylar Tape Carrier	<u>190730066</u>
Avikrimp Ring Tongue Terminal for 14 to 16 AWG Wire, Stud Size 6 (M3.5), Length 20.32mm, Mylar Tape Carrier	<u>190730070</u>
Avikrimp Ring Tongue Terminal for 14 to 16 AWG Wire, Stud Size 8 (M4), Length 20.32mm, Mylar Tape Carrier	<u>190730073</u>
Avikrimp Ring Tongue Terminal for 14 to 16 AWG Wire, Stud Size 1/4" (M6), Length 27.36mm, Mylar Tape Carrier	<u>190730077</u>
Avikrimp Ring Tongue Terminal for 14 to 16 AWG Wire, Stud Size 5/16" (M8), Length 27.36mm, Mylar Tape Carrier	<u>190730080</u>

	Avikrimp Ring	<u>190730084</u>
	Tongue Terminal for	
	14 to 16 AWG Wire,	
	Stud Size 6 (M3.5),	
	Length 22.48mm,	
	Mylar Tape Carrier	
	Avikrimp Ring	<u>190730086</u>
	Tongue Terminal for	
	14 to 16 AWG Wire,	
	Stud Size 8 (M4),	
	Length 22.48mm,	
	Mylar Tape Carrier	
	Avikrimp Ring	<u>190730088</u>
	Tongue Terminal for	
	14 to 16 AWG Wire,	
	Stud Size 10 (M5),	
	Length 22.48mm,	
	Mylar Tape Carrier	
	Avikrimp Ring	<u>190730096</u>
	Tongue Terminal for	
	14 to 16 AWG Wire,	
	Stud Size 8 (M4),	
	Length 23.77mm,	
	Mylar Tape Carrier	
	Avikrimp Ring	<u>190730099</u>
	Tongue Terminal for	
	14 to 16 AWG Wire,	
	Stud Size 10 (M5),	
	Length 23.77mm,	
	Mylar Tape Carrier	
	InsulKrimp Snap	<u>190990026</u>
	Spade for 16-14	
	AWG Wire, Stud	
	Size 5 (M3), Mylar	
	Tape Carrier, Blue	
	InsulKrimp Snap	<u>190990028</u>
	Spade for 16-14	
	AWG Wire, Stud	
	Size 6 (M3.5), Mylar	
	Tape Carrier, Blue	
	InsulKrimp Snap	<u>190990033</u>
	Spade for 16-14	
	AWG Wire, Stud	
	Size 8 (M4), Mylar	
	Tape Carrier, Length	
	22.12mm, Blue	
	InsulKrimp Snap	<u>190990035</u>
	Spade for 16-14	
	AWG Wire, Stud	
	Size 10 (M5), Mylar	
	Tape Carrier, Length	
	23.34mm, Blue	
	Avikrimp Snap	<u>191150025</u>
	Spade Terminal for	
	14-16 AWG Wire	
	Avikrimp Snap	<u>191150030</u>
	Spade Terminal for	
	14-16 AWG Wire	
	InsulKrimp Flanged	<u>191210027</u>
	Spade Tongue	
	Terminal for 14-16	
	AWG Wire, Stud	
	Size 6 (M3.5), Mylar	
	Tape Carrier	

InsulKrimp Flanged Spade Tongue Terminal for 14-16 AWG Wire, Stud Size 8 (M4), Mylar Tape Carrier	<u>191210029</u>
InsulKrimp Flanged Spade Tongue Terminal for 14-16 AWG Wire, Stud Size 10 (M5), Length 20.19mm, Mylar Tape Carrier	<u>191210031</u>
Avikrimp Flanged Spade Tongue Terminal for 14-16 AWG Wire, Stud Size 6 (M3.5), Mylar Tape Carrier	<u>191270041</u>
Avikrimp Flanged Spade Tongue Terminal for 14-16 AWG Wire, Stud Size 8 (M4), Mylar Tape Carrier	<u>191270044</u>
BLOCK SPADE AVIKRIMP TAPED (BB-8781-06T) InsulKrimp Spade Tongue Terminal for 14-16 AWG Wire, Tape and Reel	<u>191390043</u>
Avikrimp Spade Tongue Terminal for 16-14 AWG Wire, Stud Size 6 (M3.5), Mylar Tape Carrier, Length 20.45mm	<u>191440027</u>
Avikrimp Spade Tongue Terminal for 16-14 AWG Wire, Stud Size 6 (M3.5), Mylar Tape Carrier, Length 20.42mm	<u>191980013</u>
Avikrimp Spade Tongue Terminal for 16-14 AWG Wire, Stud Size 6 (M3.5), Mylar Tape Carrier, Length 20.42mm	<u>191980018</u>
Avikrimp Spade Tongue Terminal for 16-14 AWG Wire, Stud Size 8 (M4), Mylar Tape Carrier	<u>191980020</u>
Avikrimp Spade Tongue Terminal for 16-14 AWG Wire, Stud Size 10 (M5), Mylar Tape Carrier	<u>191980026</u>
Avikrimp Wire Pin Terminal for 16-14 AWG Wire, Mylar Tape Carrier	<u>192130012</u>

This document was generated on 11/02/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[63885-0400](#)