

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0639102700](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: T2 Terminator for Insulation OD 1.30-1.50mm, 22-28 AWG


Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Application Tooling
Series	207122
Comments	Can be installed in the TM42 and TM40 Press or Base Unit Adapter for 3BF Press, See Tooling Specification (PDF) Above
Function	Crimp
Geographic Area	Global
Level of Automation	Semi-Automatic
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	T2
Tool Type	Terminator Die
UPC	800756901596
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Reference - Drawing Numbers
[Application Tooling Documents](#)

ATS-639102700-001, TM-638000029-001, TM-638000029CN-001, TM-638000029DE-001, TM-638000029FR-001, TM-638000029IT-001, TM-638000029JP-001, TM-638000029KR-001, TM-638000029MY-001, TM-638000029PL-001, TM-638000029RU-001, TM-638000029SK-001, TM-638000029SP-001, TM-638000029TH-001, TM-638000029TW-001, TM-638000029VN-001, TM-638500090-001, TM-638500090SP-001

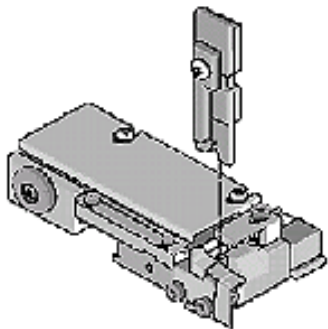

Series image - Reference only

EU ELV Not Reviewed	
EU RoHS Not Reviewed	China RoHS
REACH SVHC Not Reviewed	
Halogen-Free Status Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[207122 Series](#)

Use With
Molex TM-42 Press [690025001](#) and Base Unit [11193001](#) for the 3BF Press

Application Tooling Description	FAQ Product #
Mini-Fit Female Crimp Terminal, Tin (Sn) over Copper (Cu) Plated Brass, 22-28 AWG, Reel	39000046
Mini-Fit Male Crimp Terminal, Tin (Sn) over Plated Brass Contact, 22-28 AWG, Reel	39000048
Mini-Fit Female Crimp Terminal, Tin (Sn) over Phosphor Bronze, 22-28 AWG, Reel	39000065
Mini-Fit Male Crimp Terminal, Tin (Sn) over Phosphor	39000067

Bronze, 22-28 AWG,
Reel
Mini-Fit Male Crimp 39000122
Terminal, Tin (Sn),
Brass, 22-28 AWG,
Reel
Mini-Fit Male Crimp 39000128
Terminal, Tin (Sn),
Phosphor Bronze,
22-28 AWG, Reel
Mini-Fit Female 39000139
Crimp Terminal,
Selective Gold (Au)
and Selective Tin
(Sn) over Nickel (Ni),
22-28 AWG, Reel
Mini-Fit Male Crimp 39000145
Terminal, Brass,
Gold (Au) Contact
Plating, Lead-free,
22-28 AWG, Reel
Mini-Fit Female 39000183
Crimp Terminal,
Selective Gold (Au)
over Phosphor
Bronze, 22-28 AWG,
Reel
Mini-Fit Female 39000209
Crimp Terminal, Tin
(Sn) over Nickel (Ni),
22-28 AWG, Reel
Mini-Fit Female 39000215
Crimp Terminal, Tin
(Sn) over Phosphor
Bronze, 22-28 AWG,
Reel
Mini-Fit Male Crimp 39000221
Terminal, Phosphor
Bronze, Gold (Au),
22-28 AWG, Reel
Mini-Fit Male Crimp 39000432
Terminal, Brass,
Gold (Au) Contact
Plating, Lead-free,
22-28 AWG, Reel
Mini-Fit Female 39000434
Crimp Terminal,
Selective Gold (Au)
and Selective Tin
(Sn) over Nickel (Ni),
22-28 AWG, Reel
Mini-Fit Plus High 460182541
Mating Cycle Female
Crimp Terminal,
22-24 AWG,
Reel, Select Gold
(Au) Plating with
Proprietary Molex
Advanced Contact
Surface Finish (CSF)
in Contact Area

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[63910-2700](#)