

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0639118800

Status:

Active

Overview:

Application Tooling

Description:

T2 Terminator for insulation OD 1.10-1.30mm - 20-24 AWG

Documents:


RoHS Certificate of Compliance (PDF)

General	
Product Family	Application Tooling
Series	207122
Comments	See Tooling Specification (PDF) Above
Function	Crimp
Geographic Area	Global
Level of Automation	Automatic, Semi-Automatic
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	T2
Tool Type	Terminator Die
UPC	884982220591
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Physical	
Net Weight	885.483/g

Material Info

Reference - Drawing Numbers	
Application Tooling Documents	ATS-639118800-001, TM-638000029-001, TM-638000029CN-001, TM-638000029DE-001, TM-638000029FR-001, TM-638000029IT-001, TM-638000029JP-001, TM-638000029KR-001, TM-638000029MY-001, TM-638000029PL-001, TM-638000029RU-001, TM-638000029SK-001, TM-638000029SP-001, TM-638000029TH-001, TM-638000029TW-001, TM-638000029VN-001, TM-638500090-001, TM-638500090SP-001

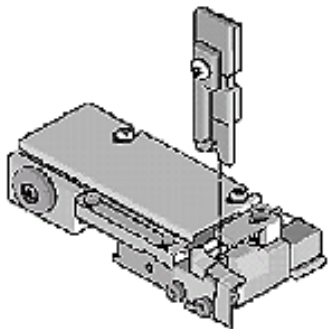

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

207122 Series

Use With

Molex TM-42 Press 690025001 and Base Unit 11193001 for the 3BF Press

Application Tooling Description	FAQ Product #
Micro-Fit 3.0 Crimp Terminal, Female, with Tin (Sn) Plated Phosphor Bronze Contact, 20-24 AWG, Reel	430300001
Micro-Fit 3.0 Crimp Terminal, Female, with Select Gold (Au) Plated Phosphor Bronze Contact, 20-24 AWG, Reel	430300002
Micro-Fit 3.0 Crimp Terminal, Female, with Select Gold (Au) Plated Phosphor Bronze Contact, 20-24 AWG, Reel	430300003

Micro-Fit 3.0 Crimp	<u>430310001</u>
Terminal, Male,	
with Tin (Sn) Plated	
Phosphor Bronze	
Contact, 20-24 AWG,	
Reel	
Micro-Fit 3.0 Crimp	<u>430310002</u>
Terminal, Male,	
with 0.38µm Select	
Gold (Au) Plated	
Phosphor Bronze	
Contact, 20-24 AWG,	
Reel	
Micro-Fit 3.0 Crimp	<u>430310003</u>
Terminal, Male,	
with 0.76µm Select	
Gold (Au) Plated	
Phosphor Bronze	
Contact, 20-24 AWG,	
Reel	
Micro-Fit TPA Crimp	<u>430315003</u>
Terminal, Male, with	
Tin (Sn) Pre-plated	
Phosphor Bronze	
Contact, 20-24 AWG,	
Reel	
Micro-Fit 3.0 Crimp	<u>457730001</u>
Terminal, Female,	
with Lubricant, with	
Tin (Sn) Plated	
Phosphor Bronze	
Contact, 20-24 AWG,	
Reel	
Micro-Fit 3.0 Crimp	<u>457730003</u>
Terminal, Female,	
with Lubricant, with	
Gold (Au) Plated	
Phosphor Bronze	
Contact, 20-24 AWG,	
Reel	
Micro-Fit 3.0 Crimp	<u>457730053</u>
Terminal, Female,	
with Lubricant, with	
Gold (Au) Plated	
Phosphor Bronze	
Contact, 20-24 AWG,	
Reel	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[63911-8800](#)