

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0639123200](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: T2 Terminator for Female Crimp Terminal

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Application Tooling
Series [207122](#)
Comments Can be installed in the TM42 and TM40 Press or Base Unit Adapter for 3BF Press, See Tooling Specification (PDF) Above

Function Crimp
Geographic Area Global
Level of Automation Semi-Automatic
More Detailed Tech Information applicationtooling@molex.com
Overview Application Tooling
Product Name T2
Tool Type Terminator Die
UPC 884982667044
Warranty Disclaimer CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Physical
Net Weight 940.710/g

Material Info

Reference - Drawing Numbers
Application Tooling Documents
ATS-639123200-001, TM-638000029-001, TM-638000029CN-001, TM-638000029DE-001, TM-638000029FR-001, TM-638000029IT-001, TM-638000029JP-001, TM-638000029KR-001, TM-638000029MY-001, TM-638000029PL-001, TM-638000029RU-001, TM-638000029SK-001, TM-638000029SP-001, TM-638000029TH-001, TM-638000029TW-001, TM-638000029VN-001, TM-638500090-001, TM-638500090SP-001

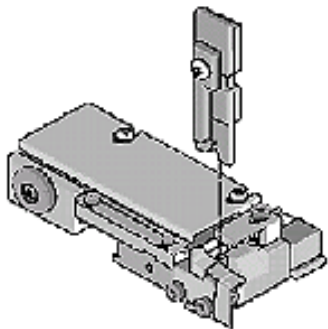

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Not Reviewed
REACH SVHC
Not Reviewed
Halogen-Free
Status
Not Relevant
For more information, please visit [Contact US](#)

China ROHS Not Relevant
ELV Not Relevant
RoHS Phthalates Not Reviewed

Search Parts in this Series
[207122 Series](#)

Use With
Molex TM-42 Press [690025001](#) and Base Unit [11193001](#) for the 3BF Press

Application Tooling Description	FAQ Product #
SL Crimp Terminal, Series 70058, Female, 22-24 AWG, with Tin (Sn) Plated Contact, Reel	16020086
SL Crimp Terminal, Series 70058, Female, 22-24 AWG, with 0.38µm Selective Gold (Au) Plated Contact, Reel	16020087
SL Crimp Terminal, Series 70058, Female, 22-24 AWG, with 0.76µm Selective Gold (Au) Plated Contact, Reel	16020088

SL Crimp Terminal, [16021110](#)
Series 71851,
Female, with Tin
(Sn) Plated Contact,
22-24 AWG, Reel
SL Crimp Terminal, [16021111](#)
Series 71851,
Female, with 0.76µm
Selective Gold (Au)
Plated Contact,
22-24 AWG, Reel
SL Crimp Terminal, [16021124](#)
Series 71851,
Female, with 0.38µm
Selective Gold (Au)
Plated Contact,
22-24 AWG, Reel
SL Crimp Terminal, [700584086](#)
Series 70058,
Female, 22-24 AWG,
with Tin (Sn) Plated
Contact, Unplated
Edges, Reel

This document was generated on 11/02/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[63912-3200](#)