

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION


Part Number: [0640060200](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: Manual Arbor Press, SC Power Connector

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General
Product Family Application Tooling
Series [207125](#)
Function Insulation Displacement (IDT)
Geographic Area Global
Level of Automation Manual
More Detailed Tech Information applicationtooling@molex.com
Overview [Application Tooling](#)
Product Name N/A
Tool Type Arbor Press
UPC 822348127054
Warranty Disclaimer CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Reference - Drawing Numbers
Application Tooling Documents [ATS-640060200-001](#)

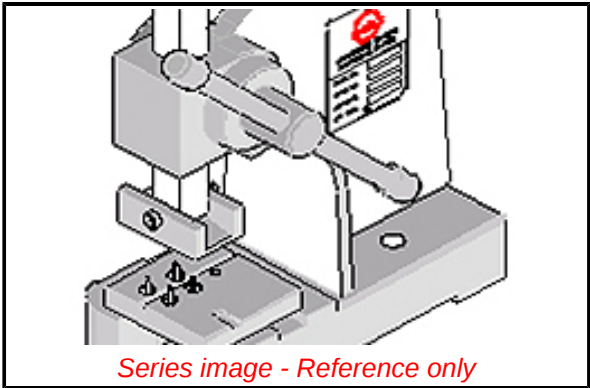

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[207125 Series](#)

Application Tooling Description	FAQ Product #
Self-Contained Power Connector for Solid Nonmetallic Sheathed Cable, 12-14 AWG	190451000
Self-Contained Power Connector for Solid Nonmetallic Sheathed Cable, 12-14 AWG	194011000
Self-Contained Tap Splice Connector for Solid Nonmetallic Sheathed Cable, 12-14 AWG	194021000
Self-Contained Power Connector for 2 Circuit Round Cable with Ground, 14 AWG, Insulation Diameter 15.24mm	194030011

Self-Contained Power Connector for Stranded Nonmetallic Sheathed Cable, 12 AWG	<u>194031010</u>
Self-Contained Power Connector for Stranded Nonmetallic Sheathed Cable, 14-16 AWG	<u>194031011</u>
Self-Contained Power Connector for Solid or Stranded Nonmetallic Sheathed Cable, 10 AWG	<u>194031300</u>
Self-Contained Power Connector for 2 Circuit Round Cable with Ground, 14 AWG, Insulation Diameter 8.64-11.18mm	<u>194031310</u>
Self-Contained Power Connector for 2 Circuit Round Cable with Ground, 12 AWG, Insulation Diameter 8.64-11.18mm	<u>194210001</u>
Self-Contained Power Connector for 2 Circuit Round Cable with Ground, 12 AWG, Insulation Diameter 15.24mm	<u>194210002</u>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[64006-0200](#)