

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0903270374

Status:

Active

Overview:

Picoflex Ribbon-Cable Connectors

Description:

Picoflex PF-50, Low Profile, IDT Receptacle, 14 Circuits, White, Tin (Sn) Plated, Reeling Option D

Documents:

3D Model

3D Model (PDF)

Drawing (PDF)

Product Specification PS-99020-0011-001 (PDF)

Packaging Specification PK-90327-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

UL

LR19980

E29179

General

Product Family

Series

Comments

Component Type

Glow-Wire Capable

Overview

Product Name

UPC

Ribbon Cable / Wire Trap Connectors

90327

Low Profile|Reeling Option D

Housing

No

Picoflex Ribbon-Cable Connectors

Picoflex

800753672697

Physical

Circuits (Loaded)

Circuits (maximum)

Color - Resin

Durability (mating cycles max)

Entry Angle

Flammability

Lock to Mating Part

Material - Metal

Material - Plating Mating

Material - Plating Termination

Material - Resin

Net Weight

Number of Rows

PCB Locator

PCB Retention

Packaging Type

Pitch - Mating Interface

Pitch - Termination Interface

Polarized to Mating Part

Polarized to PCB

Shrouded

Stackable

Surface Mount Compatible (SMC)

Temperature Range - Operating

Termination Interface: Style

Wire Insulation Diameter

Wire Size AWG

Wire/Cable Type

14

14

White

30

Vertical

94V-0

Yes

Phosphor Bronze

Tin

Tin

Polyester

0.836/g

2

No

None

Embossed Tape on Reel

1.27mm

1.27mm

Yes

No

Fully

No

N/A

-40° to +105°C

IDT or Pierce

1.00mm max.


26, 28

Ribbon Cable

Electrical

Current - Maximum per Contact

1.2A

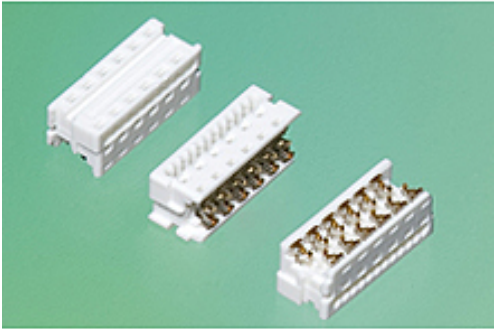

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per -

D(2021)4569-DC (8

July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

90327 Series

Mates With

Low Profile Vertical 90325 , Low Profile Right Angle 90800 , 90715 , 90814 , 90779 Vertical, 91714 1.27mm Pitch Picoflex PF-50 Header

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Extractor Tool for Connectors	621006000
Extraction Tool for Picoflex PF-50 Connectors, 4-26 Circuits	690081070

Voltage - Maximum	250V	Semi-Automatic Bench Press PB14 for 4-26 Circuit	<u>691271001</u>
Material Info		Semi-Automatic PB14 Bench Press with Auto De-reeling	<u>691271004</u>
Reference - Drawing Numbers		Assembly of De-Tape Unit for PB14 Part Number	<u>691275045</u>
Packaging Specification	PK-90327-001-001		
Product Specification	PS-99020-0011-001		
Sales Drawing	SDA-90327-001, SDA-90327-002		

This document was generated on 09/13/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[90327-0374](#)