

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0903273384

Status:

Active

Overview:

Picoflex Ribbon-Cable Connectors

Description:

Picoflex PF-50, Low Profile, IDT Receptacle, 20 Circuits, White, Gold (Au) Plated, Reeling Option B

Documents:

3D Model

Drawing (PDF)

3D Model (PDF)

Product Specification PS-99020-0011-001 (PDF)


Packaging Specification PK-90327-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Ribbon Cable / Wire Trap Connectors
Series	90327
Comments	Low Profile Reeling Option B
Component Type	Housing
Glow-Wire Capable	No
Overview	Picoflex Ribbon-Cable Connectors
Product Name	Picoflex
UPC	800753015142

Physical	
Circuits (Loaded)	20
Circuits (maximum)	20
Color - Resin	White
Durability (mating cycles max)	100
Entry Angle	Vertical
Flammability	94V-0
Lock to Mating Part	Yes
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Material - Resin	Polyester
Net Weight	3.034/g
Number of Rows	2
PCB Locator	No
PCB Retention	None
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	1.27mm
Pitch - Termination Interface	1.27mm
Polarized to Mating Part	Yes
Polarized to PCB	No
Shrouded	Fully
Stackable	No
Surface Mount Compatible (SMC)	N/A
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	IDT or Pierce
Wire Insulation Diameter	1.00mm max.
Wire Size AWG	26, 28
Wire/Cable Type	Ribbon Cable

Electrical	
Current - Maximum per Contact	1.2A

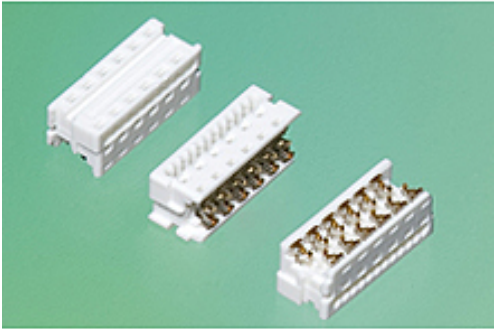

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

90327 Series

Mates With

Low Profile Vertical 90325 , Low Profile Right Angle 90800 , 90715 , 90814 , 90779 Vertical, 91714 1.27mm Pitch Picoflex PF-50 Header

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Extractor Tool for Connectors	621006000
Extraction Tool for Picoflex PF-50 Connectors, 4-26 Circuits	690081070

Voltage - Maximum	250V	Semi-Automatic Bench Press PB14 for 4-26 Circuit	<u>691271001</u>
Material Info		Semi-Automatic PB14 Bench Press with Auto De-reeling	<u>691271004</u>
Reference - Drawing Numbers		Assembly of De-Tape Unit for PB14 Part Number	<u>691275045</u>
Packaging Specification	PK-90327-001-001		
Product Specification	PS-99020-0011-001		
Sales Drawing	SDA-90327-002		

This document was generated on 12/13/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

90327-3384