

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0936060434

Status:


Active

Overview:

GWconnect® Heavy Duty Connectors (HDC)

Description:

GWconnect Patch Cord Cable Assembly, CAT5 (CAT5e) Plug-to-Plug, 8P/8C Wiring, Fully Shielded, Size 3A «21x21» , HE - Harsh Environment Black Metal Hood, Side Entry, M20 Metal Gland, 1.50m

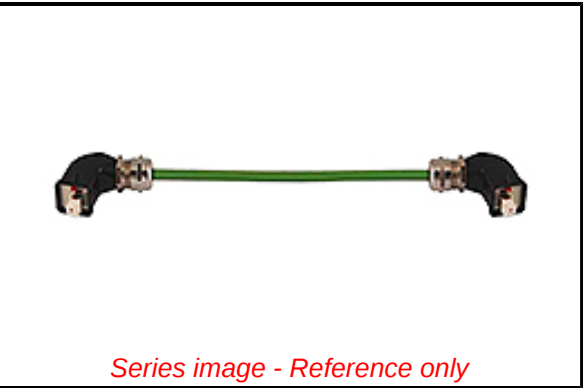

Documents:

RoHS Certificate of Compliance (PDF)

General	
Product Family	Industrial Connectors / Enclosures
Series	93606
Boot	No
Cable Gland Type	IP66 - Basic
Color - Cable Jacket	Green
Comments	Class D up to 100 MHz acc. to ISO/IEC 11802
Component Size	3A «21x21»
Component Type	Cable Assembly
IP Rating	IP66, IP67
Length	1.50m
Material - Outer Jacket	PUR
Overview	GWconnect® Heavy Duty Connectors (HDC)
Product Category	Patch Cords
Product Name	GWconnect
Standard	EN 50173-1
Type	RJ45 CAT5
UPC	887191858852
Physical	
Cable Diameter	6.80mm
Entry Location	Side
Gender	Plug/Plug
Hood Color	Black RAL 9005
Lock to Mating Part	Yes
Material - Cable Gland	Metal
Material - Hood	Die-cast Aluminum
Material - Nut	Metal
Material - Plating	Gold
Material - Plug	PBT
Packaging Type	Bag
Polarized to Mating Part	Yes
Poles	8p/8C
Temperature Range - Operating	-20°C to +70°C
Thread Size	M20
Thread Type	(M) Metric
Wire Size AWG	26
Material Info	
Engineering Number	2980.3247.B

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

China RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Not Reviewed

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

93606 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

93606-0434