


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1062841004](#)
Status: **Active**
Overview: [Optical Connectivity Solutions](#)
Description: CXP Optical Cable Assembly (iPass+), MTP-to-MTP, Multimode, 50/125µm, Round Cable Assembly, Straight Boot, High Bandwidth, OFNR, Cable Diameter 4.50mm, Cable Length 4.00m

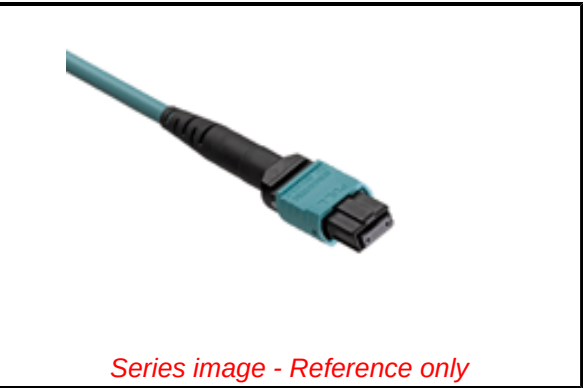

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Fiber Optic Assemblies
Series	106284
Boot Type	Straight
Connector to Connector	MTP-to-MTP
Mode	Multimode
Overview	Optical Connectivity Solutions
Product Name	CXP, iPass+, MTP
UPC	884982912397
Physical	
Cable Length	4.0m
Cable Size	3.80mm
Fiber (Core/Cladding)	50/125µm
Net Weight	80.900/g
Single Ended	No
Wire/Cable Type	Fiber Optic, Round
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SD-106284-0001-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2021)4569-DC (8 July 2021)	
Lead	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[106284](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[106284-1004](#)