


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1120115035](#)
Status: **Active**
Overview: [PC Network Interface Cards](#)
Description: PCU-DP2IO PROFIBUS-DP Master/Slave 12 Mbps, PCI Express 1x

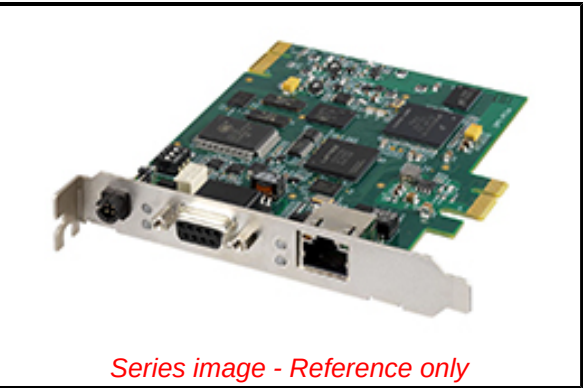

Documents:
[Datasheet \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Network Interface
Series	112011
Application	IO Control
Approvals	CE certified
Overview	PC Network Interface Cards
Product Name	applicom IO
Protocol	PROFIBUS
Protocol Detail	PROFIBUS DPV0 Master, PROFIBUS DPV0 Slave, PROFIBUS DPV1 Master
Software Downloads	DRL-DPM-PCIE
Type	PROFIBUS Card
UPC	887191524191
Physical	
Channels	1
Communication Speed	PROFIBUS 9.6 kbps to 12 Mbps
Interface	DLL, OPC DA
Mounting Style	PC Slot
Net Weight	115.000/g
Network Connection Type	PROFIBUS D-Sub Female (9 pin)
Operating System	Windows7, Windows8/8.1, Windows Server 2003, Windows Server 2008, Windows Server 2012, Windows Vista, WindowsXP
Packaging Type	Carton
Processor	PowerPC 8323
Slot	Universal PCI 3.3V/5V
Temperature Range - Operating	0°C to +60°C
Electrical	
Current - Maximum Input	5.5W
EMC	EN 55022 Class B, EN 61000-3-2, EN 61000-3-3, IEC 61000-6-2
Supply Voltage	3.3V
Material Info	
Engineering Number	DR2-DPM-PCIE

EU ELV Not Relevant	
EU RoHS Compliant with Exemption 6(c),7(c)-I,7(a) REACH SVHC Not Reviewed Halogen-Free Status Not Relevant	China RoHS
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[112011](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

1120115035